

DURATOOL



Butane Gas Torch - Adjustable
Model: D03356

IMPORTANT SAFETY INFORMATION


- Never point the tool towards yourself or towards others when lighting or during use.
- Do not touch the tip, nozzle or the main tube when hot.
- Contains flammable gas contents under pressure.
- Do not expose to sparks or naked flame.
- Do not puncture or incinerate the unit.
- Store at temperatures below 40°C (104°F)
- Use only in a well ventilated area.
- This appliance is not intended for use by persons (including children) who are not mentally able, physically capable, experienced or do not understand the product. They should be given supervision and instruction in the use of the appliance by a person responsible for their safety.
- Children should be supervised to ensure that they do not play with the appliance.
- There are no user serviceable parts inside, do not disassemble the unit.
- Ensure the flame is fully extinguished and the torch allowed to cool after use before putting into storage.

REFILLING

- Invert the torch then firmly insert the refill canister nozzle into the filling valve under the base of the torch keeping it perpendicular at all times and press.
- Only use triple refined Butane refill gas.
- The torch will only take a few seconds to fill, then allow a couple of minutes for the gas to stabilise before using the torch.

OPERATION

- Turn the air adjustment ring to expose the air inlet port fully before ignition.
- Set the safety lock control to the right 'ON' position.
- Switch the continuous flame control to the right 'OFF' position.
- Press the ignition button.
- For short term usage hold the ignition button down, release to extinguish the flame.
- To use continuously while holding the ignition button down, slide the continuous flame control to the left 'ON' position and release the ignition button.
- To adjust the flame length, turn the gas flow control to '+' to increase or '-' to reduce.
- Rotate the air adjustment ring to change the flame intensity.
- Switching the continuous flame switch to the right 'OFF' position extinguishes the flame.

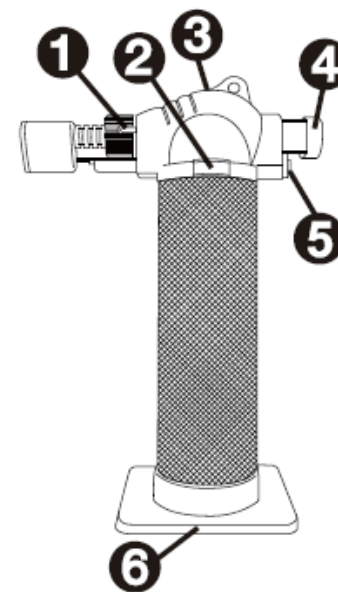

1. Air adjustment port control
2. Continuous flame ring
3. Gas flow control
4. Ignition button
5. Safety lock out control
6. Refill valve under base

SPECIFICATION

Weight	164g
Fuel	Butane (25ml)
Operating time	Approx 30-40 minutes
Dimensions (H x W x D)	105 x 67 x 157mm
Flame temperature	Up to 1300°C (blue flame)



Made in Taiwan
PR2 9PP
PO Box 13362 Dublin 2

Man Rev 1.1