

DURATOOL



Hand Held Butane Gas Torch
Model: D03362

IMPORTANT SAFETY INFORMATION


- Never point the tool towards yourself or towards others when lighting or during use.
- Do not touch the tip, nozzle or the main tube when hot.
- Contains flammable gas contents under pressure.
- Do not expose to sparks or naked flame.
- Do not puncture or incinerate the unit.
- Store at temperatures below 40°C (104°F)
- Use only in a well ventilated area.
- This appliance is not intended for use by persons (including children) who are not mentally able, physically capable, experienced or do not understand the product. They should be given supervision and instruction in the use of the appliance by a person responsible for their safety.
- Children should be supervised to ensure that they do not play with the appliance.
- There are no user serviceable parts inside, do not disassemble the unit.
- Ensure the flame is fully extinguished and the iron allowed to cool after use before putting into storage.

REFILLING

- Invert the torch then firmly insert the refill canister nozzle into the filling valve under the base of the torch keeping it perpendicular at all times and press.
- Only use high quality Butane refill gas.
- The iron will only take a few seconds to fill, then allow a couple of minutes for the gas to stabilise before using the torch.

OPERATION

- Set the safety lock control to the left 'OFF' position.
- Switch the gas flow control to the centre position.
- Press the ignition button to ignite the flame.
- For short term usage hold the ignition button down, release to extinguish the flame.
- To use continuously while holding the ignition button down, slide the lock control to the left 'ON' position and release the ignition button.
- To adjust the flame length, slide the gas flow control to '+' to increase or '-' to reduce.
- Switching the lock switch to the left 'OFF' position extinguishes the flame.
- To prevent accidental ignition prior to storage when the tool has cooled down switch the lock to 'ON' position.

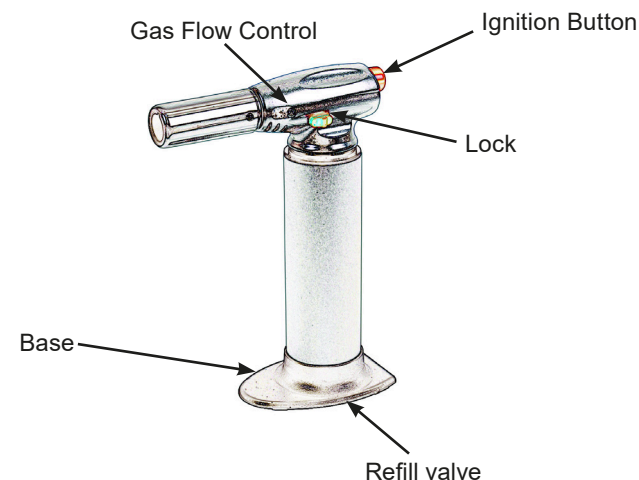

SPECIFICATION

Weight	295g
Fuel	Butane
Operating time	Approx 60 minutes
Dimensions (H x W x D)	72 x 173 x 227mm
Flame temperature	Up to 1300°C

