

Product information

86 02 250

Pliers Wrenches

Pliers and a wrench in a single tool




- Replaces the need for sets of metric and imperial spanners
- Smooth jaws for damage free installation of plated fittings - working directly on chrome!
- With scaling for presetting the width apart from the workpiece
- Adjustable tightening tool
- Also excellent for gripping, holding, pressing and bending workpieces
- Push the button for adjustment on the workpiece
- Zero backlash jaw pressure prevents damage to edges of sensitive components
- Parallel jaws give a more solid grip; its design allows flexible adjustment of all widths up to the specified maximum size
- Reliable catching of the hinge bolt: no unintentional shifting
- The ratchet type principle allows quick and easy tightening and release of all bolted connections
- Lever transmission greater than 10 : 1 for strong gripping power
- Chrome vanadium electric steel, forged, oil-hardened

General

Article No.	86 02 250
EAN	4003773082392
Pliers	black atramentized
Head	polished
Handles	with multi-component grips
Weight	485 g
Dimensions	250 x 55 x 18 mm
REACH compliant	no
RohS compliant	no

Technical details

Jaw thickness (joint) (B2)	8.0 mm
Joint thickness (B3)	14.0 mm
Tips thickness (B1)	8.0 mm
Adjustment positions	19
Capacities for nuts	Ø 2 Inch
Capacities for nuts	52 mm

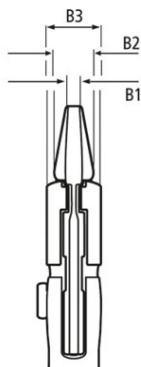

Classification

eCl@ss 5.1.4	21043826
proficl@ss 6.0	AAA936c004
UNSPSC 13.1	27112112

Accessories

86 09 250 V01

Protective jaws for 86 XX 250, 3 pairs

technical change and errors excepted

