


## Dual-Monitor USB 3.0 Docking Station with DVI and Vertical Stand

**Product ID:** USB3SDOCKDD

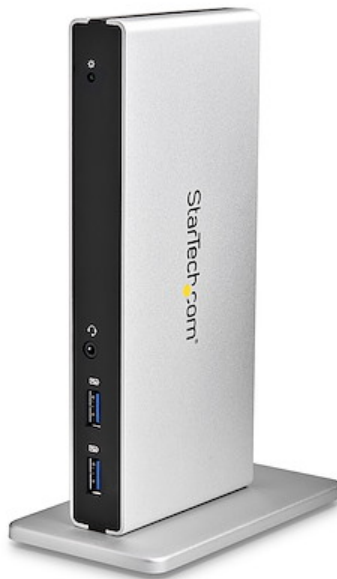

This dual-monitor USB 3.0 docking station turns your laptop into a dual-monitor workstation with flexible setup options.

The dual-DVI docking station adds dual-monitor support to your workstation, with resolution support up to 2048x1152. With more screen space, you can simultaneously access multiple applications and reference material on one display while composing on the other. To ensure the USB 3.0 dock supports a variety of displays, two display adapters (DVI to VGA and DVI to HDMI) are included.

Transform your laptop into a workstation that supports all of your peripherals. This docking station features five USB 3.0 (USB 3.1 Gen 1) ports. The two front-facing USB ports are USB fast-charge ports (USB Battery Charging Specification 1.2). These accessible ports charge your mobile devices faster than standard USB ports, with or without your laptop connected to the dock. The dock also has a GbE port, headset jack and separate 3.5 mm audio and mic ports, so you'll have all the connections you need.

You can free up valuable desk space by positioning the dock vertically on your work surface using the included (optional) stand.

The USB3SDOCKDD is backed by a 3-year StarTech.com warranty and free lifetime technical support.

## Certifications, Reports and Compatibility

### Applications

- Use dual displays to work on multiple documents simultaneously in office applications
- View multiple monitors at a glance, in financial or investment firms
- Create a quick-connect workstation that supports your existing HDMI, VGA, and DVI monitors

## Features

- Dock your USB 3.0 equipped Mac or Windows laptop with support for several dual monitor configurations using the included video adapters
- Connect and charge your USB devices with 5x USB 3.0 ports, including two Fast-Charge USB ports
- Save space on your desktop by placing the dock in a vertical orientation with the included dock stand
- Add wired network connectivity and audio devices with the Gigabit Ethernet RJ-45 port and headset jack.

---

## Hardware

Warranty	3 Years
4K Support	No
Fast-Charge Port(s)	Yes
Displays Supported	2
Bus Type	USB 3.0
Industry Standards	IEEE 802.3, IEEE 802.3u, IEEE 802.3ab USB Battery Charging Specification Rev. 1.2 USB 3.0 - Hub ports support USB 2.0/1.1 backward-compatibility
Chipset ID	DisplayLink - DL-3900 Genesys Logic - GL3520, VIA/VLI - VL817

---

## Performance

Maximum Data Transfer Rate	5 Gbps (USB 3.0) 2 Gbps (Ethernet; Full-Duplex)
Maximum Analog Resolutions	2048x1152 (VGA)
Maximum Digital Resolutions	2048x1152 (Dual-Link DVI/HDMI) Lower resolutions are also supported.
Type and Rate	USB 3.0 - 5 Gbit/s
UASP Support	Yes
Compatible Networks	10/100/1000 Mbps

	Auto MDIX	Yes
	Full Duplex Support	Yes
<b>Connector(s)</b>		
	Connector Type(s)	DVI-D (25 pin) DVI-I (29 pin) USB 3.0 A (Fast-Charge, 9 pin) USB Type-A (9 pin, 5 Gbps) RJ-45 3.5 mm Mini-Jack (4 Position) USB Type-B (9 pin) USB 3.0
<b>Software</b>		
	OS Compatibility	Windows XP SP3 (32-bit), Vista, 7, 8, 8.1, 10, 11 macOS 10.6 - 10.12, 10.14 - 10.15, 11.0, 12.0 Chrome OS v55+
<b>Special Notes / Requirements</b>		
	System and Cable Requirements	USB 3.0 port interface and USB 3.0 cable to connect the Laptop Docking Station to a host computer (USB 3.0 host cable included)
	Note	HDMI and VGA adapters included VGA adapter can only be used on the DVI-I (29-pin) port The DVI-I connector supports DVI-I signaling (digital and analog) This USB docking station is not intended for graphical intensive applications, such as gaming
<b>Indicators</b>		
	LED Indicators	Power
<b>Power</b>		
	Power Source	AC Adapter Included
	Input Voltage	100 - 240 AC

Input Current	0.7A
Output Voltage	12V DC
Output Current	2A
Center Tip Polarity	Positive
Plug Type	H
Power Consumption (In Watts)	24W

---

#### Environmental

Operating Temperature	0C to 50C (32F to 122F)
Storage Temperature	-20C to 60C (-4F to 140F)
Humidity	5~85% RH

---

#### Physical Characteristics

Color	Black & Silver
Material	Aluminum and Plastic
Cable Length	39.4 in [100 cm]
Product Length	3.3 in [83.0 mm]
Product Width	0.9 in [23.0 mm]
Product Height	7.0 in [17.8 cm]
Weight of Product	10.1 oz [285.0 g]

---

#### Packaging Information

Package Length	7.3 in [18.6 cm]
Package Width	10.0 in [25.5 cm]
Package Height	3.7 in [95.0 mm]
Shipping (Package) Weight	35.9 oz [1018.0 g]

---

#### What's in the Box

Included in Package	USB 3.0 Laptop Docking Station
---------------------	--------------------------------

1m USB 3.0 Cable

Rubber Feet

Stand

Stand Screws

Screwdriver

DVI to VGA Adapter

DVI to HDMI Adapter

Universal Power Adapter (NA/JP, EU, UK, ANZ)

Driver CD

Instruction Manual

---

***\*Product appearance and specifications are subject to change without notice.***

