

## Blank Plates


Flex Outlet  
FrontplateEuro Modular  
FrontplatesEuro Power  
Modules

20 AMP



K3825WHI

K3827WHI

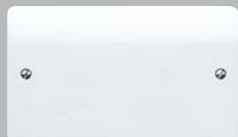

K3828WHI



K5033WHI



K1090WHI



K181WHI



K182WHI



K184WHI



K5830WHI



K5831WHI



K5832WHI



K5833WHI



K5834WHI



K5837WHI

**K3825WHI**  
1 GANG MOULDED  
ARCHITRAVE

10

**K3827WHI**  
1 GANG MOULDED

10

**K3828WHI**  
2 GANG MOULDED

10

**K5033WHI**  
METAL

1

**K3825WHI**  
For use with 3921ZIC and K2151WHI  
MOUNTING BOXES.

**K5033WHI**  
For use with 5120ALM deep metal box.

**DIMENSIONS**  
K3825WHI: 86 x 31mm  
K3827WHI: 86 x 86mm  
K3828WHI: 86 x 146mm  
K5033WHI: 178 x 165mm

**FIXING CENTRES**  
K3825WHI: 60.3mm  
K3827WHI: 60.3mm  
K3828WHI: 120.6mm  
K5033WHI: 133mm  
BS 5733:2010

**K1090WHI**  
FLEX OUTLET FRONTPLATE  
UNFUSED

10

Complete with three pairs of terminals, each  
suitable for 2 x 2.5mm<sup>2</sup> conductors and a  
1.5mm<sup>2</sup> flexible cord.  
A cord-grip is also fitted.

Frontplate thickness is 12.5mm.  
Cable entry diameter is 11mm.

**DIMENSIONS**  
86 x 86mm  
**FIXING CENTRES**  
60.3mm  
BS EN 60670-22:2006

**K181WHI**  
1 GANG EURO FRONTPLATE  
ONE MODULE

10

APERTURE SIZE 25 X 50MM

**K182WHI**  
**K182GRA**

10

10

1 GANG EURO FRONTPLATE  
TWO MODULE

APERTURE SIZE 50 X 50MM

**K184WHI**  
**K184GRA**

10

10

2 GANG EURO FRONTPLATE  
FOUR MODULE

APERTURE SIZE 100 X 50MM

**K185WHI**

10

3 GANG EURO FRONTPLATE  
SIX MODULE

APERTURE SIZE 150 X 50MM

**MOUNTING BOXES**  
Suitable for flush boxes to  
BS 4662:2006 and surface boxes to  
BS 5733:2010 Refer to appropriate  
module for minimum box depth.

**K185WHI MOUNTING BOX**  
35mm VTS8035 (For use with  
Pinnacle and Premier cable  
management systems) K2153WHI  
30mm

**FIXING CENTRES**  
1 GANG: 60.3mm 2 GANG: 120.6mm  
BS 5733:2010 where applicable

Note: No grid required, modules just  
clip into place

**K5830WHI**  
**K5830BLK**  
UK 1 GANG EURO 2 MODULE  
13A 250V SHUTTERED

1

1

**K5831WHI**  
**K5831BLK**

10

10

GERMAN 2P+E  
16A 250V SHUTTERED

EURO 2 MODULE (NON UK)

**K5832WHI**  
**K5832BLK**

10

10

AMERICAN 2P+E  
15A 127V SHUTTERED

EURO 2 MODULE (NON UK)

**K5830**  
**MOUNTING BOX**

35mm minimum  
46mm (for extra wiring space)

**DIMENSIONS**  
50 x 50mm  
BS 1363 Pt2:1995

**K5831**  
**MOUNTING BOX**

46mm  
**DIMENSIONS**  
50 x 50mm

IEC 60884-1:2006

**K5832**  
**MOUNTING BOX**

35mm  
46mm (for extra wiring space)

**DIMENSIONS**  
50 x 50mm  
SASO 2204:2003

**K5833WHI**  
**K5833BLK**  
UK 1 GANG EURO 2 MODULE  
5A 250V SHUTTERED

10

10

**K5834WHI**  
**K5834BLK**

10

10

FRENCH/BELGIAN 2P+E  
16A 250V SHUTTERED

EURO 2 MODULE (NON UK)

**K5837WHI**  
**K5837BLK**

1

1

USB CHARGING MODULE  
EURO 2 MODULE

**K5833**  
**MOUNTING BOX**

35mm minimum  
46mm (for extra wiring space)

**DIMENSIONS**  
50 x 50mm  
BS 546:1950

**K5834**  
**MOUNTING BOX**

46mm  
**DIMENSIONS**  
50 x 50mm

NF C61-314

**K5837**  
**MOUNTING BOX**

35mm, 46mm (for extra wiring space)

**DIMENSIONS**  
50 x 50mm  
USB charging sockets, each capable of  
supporting 2A charge (total of 2A).

IEC 60950-1  
IEC 61000-6-1/3