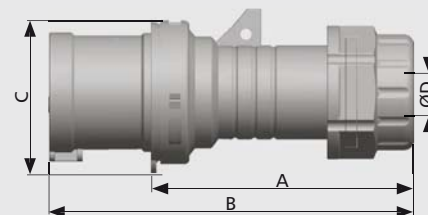


Commando Technical

mkelectric.co.uk



Plugs 16 and 32 Amp

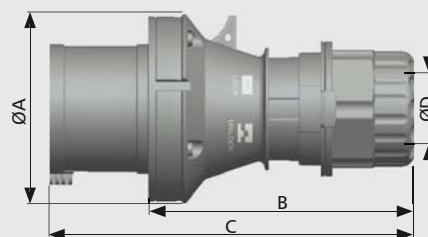
IP44 SPLASHPROOF


AMPS	PIN. CONFIGURATION	100-130V 50-60HZ	200-250V 50-60HZ	380-415V 50-60HZ	CABLE DIAMETER D MM		TERMINAL CAPACITY* MM ²	DIMENSIONS IN MM		
		LIST NO	LIST NO	LIST NO	MIN	MAX		A	B	C
16A	2P+E	K9000YEL	K9001BLU 6		8.2	13	1-2.5	132.3	95.5	55.5
16A	3P+E		K9006BLU 6	K9007RED 6	8.9	15.5	1-2.5	132.3	95.5	61.5
16A	3P+N+E		K9014BLU 9	K9015RED 6	10.1	17	1-2.5	132.3	95.5	67.5
32A	2P+E	K9032YEL 4	K9033BLU 6		11.7	18	2.5-6	135.8	90	72.5
32A	3P+E		K9036BLU	K9037RED 6	11.7	22	2.5-6	135.8	90	72.5
32A	3P+N+E		K9044BLU 9	K9045RED 6	14.2	22	2.5-6	141.8	95.8	79.7

Earth Hour Position

*Flexible conductors

Plugs 63 Amp

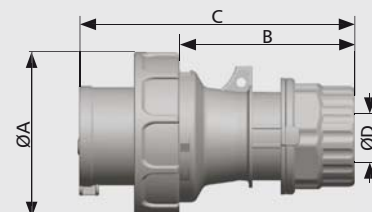
IP44 SPLASHPROOF


AMPS	PIN. CONFIGURATION	100-130V 50-60HZ	200-250V 50-60HZ	380-415V 50-60HZ	CABLE DIAMETER D MM		TERMINAL CAPACITY* MM ²	DIMENSIONS IN MM			
		LIST NO	LIST NO	LIST NO	MIN	MAX		A	B	C	D
63A	2P+E	K9063BLU 6			16.5	36	6-16	102	180.8	247.3	36.4
63A	3P+E		K9066RED 6		16.5	36	6-16	102	180.8	247.3	36.4
63A	3P+N+E			K9071RED 6	16.5	36	6-16	102	180.8	247.3	36.4

Earth Hour Position

*Flexible conductors

Plugs 16 and 32 Amp

IP67 WATERTIGHT


AMPS	PIN. CONFIGURATION	100-130V 50-60HZ	200-250V 50-60HZ	380-415V 50-60HZ	CABLE DIAMETER D MM		TERMINAL CAPACITY* MM ²	DIMENSIONS IN MM		
		LIST NO	LIST NO	LIST NO	MIN	MAX		A	B	C
16A	2P+E	K9023YEL 4	K9024BLU 6		8.2	13	1-2.5	72	81.2	117.6
16A	3P+E			K9025RED 6	8.9	17	1-2.5	75.4	87.2	123.6
16A	3P+N+E			K9026RED 6	10.1	17	1-2.5	88	93.6	129.6
32A	2P+E		K9054BLU 6		11.7	18	2.5-6	92	97.2	142.6
32A	3P+E									
32A	3P+N+E			K9056RED 6	14.2	22	2.5-6	98	102.9	148.3

Earth Hour Position

*Flexible conductors