

EZ Port Cable Economisers



Features

- Allow additional signals to be transmitted down the unused pairs of 4 pair cable
- Used in pairs, one at each end of the cabling
- Wiring diagram on housing
- Provides for instant network expansion
- Available in 2, 3 and 4 port variants
- Performance – meets Category 5e transmission standard
- Supplied with self adhesive pad

Specifications

2 port

- Housing (mm) 37 x 43 x 22 / Tail 145 (approx)
- ADF-S Housing (mm) 42 x 44 x 32 / Tail 150 (approx)

3 port


- Housing (mm) 56 x 43 x 26 / Tail 145 (approx)

4 port

- Housing (mm) 72 x 43 x 26 / Tail 145 (approx)
-

Materials


- Outer casing: ABS
- Cable: Cat5e 24 AWG

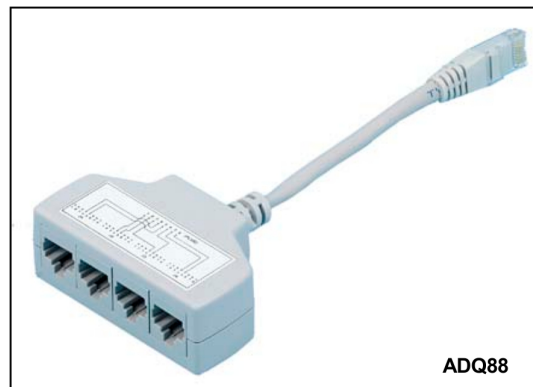


Not suitable for use with PoE

ADF (Housing: Black, Tail: Grey)


ADF-S (Housing: Silver, Tail: Grey)

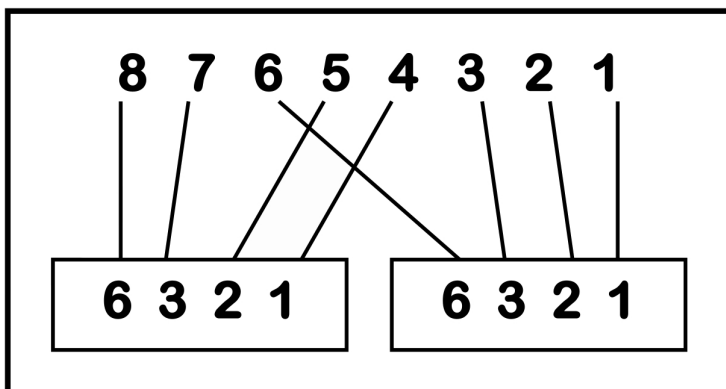


ADF5 (Housing: Black, Tail: Grey)

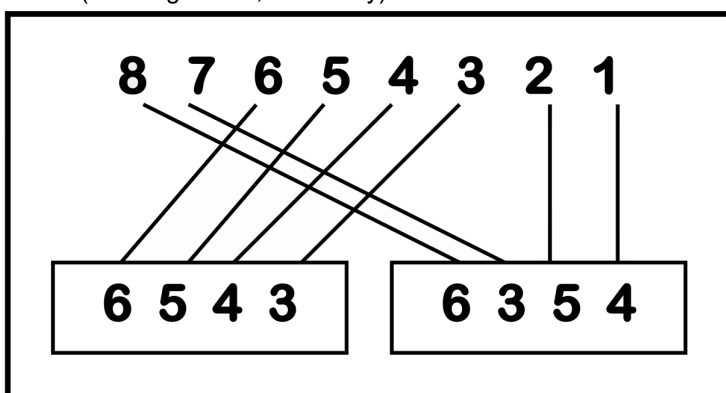


ADF6 (Housing: Black, Tail: Grey)

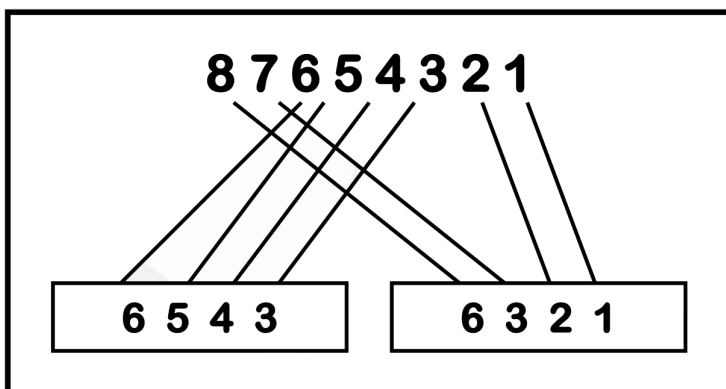


ADFDim (Housing: Black, Tail: Black)

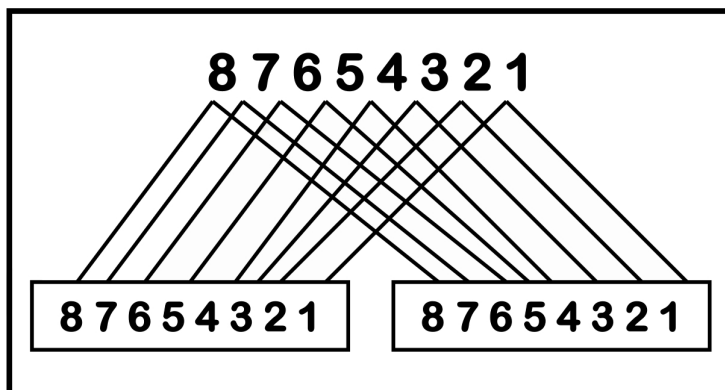


ADFvWh5 (Housing: White, Tail: White)

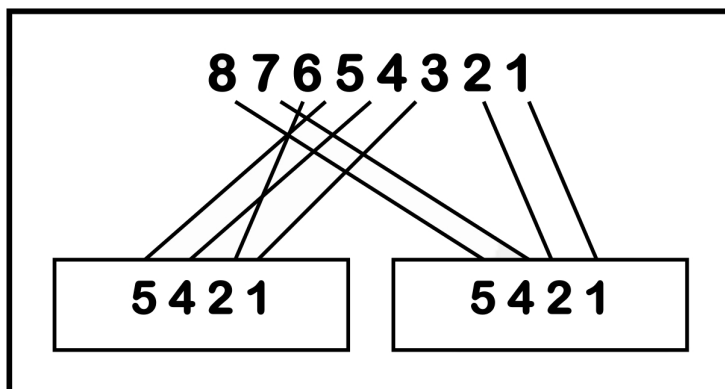


ADFwh6 (Housing: White, Tail: White)

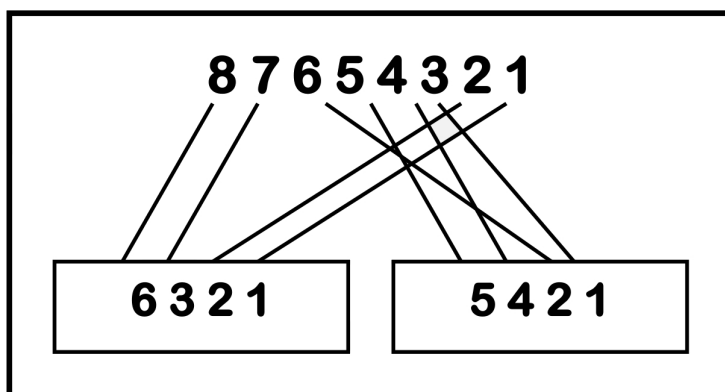

ADT2 (Housing: Black, Tail: Black)

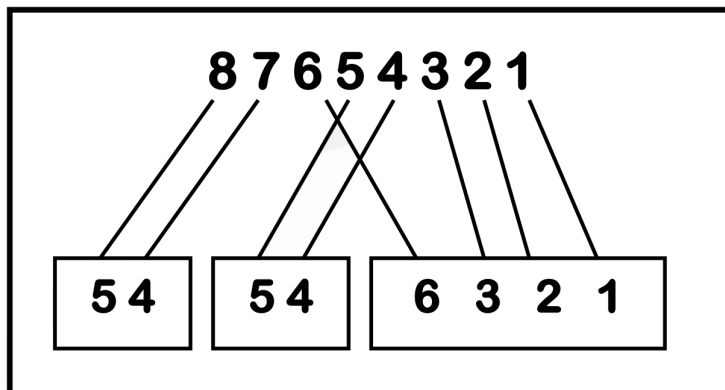

ADQ64 (Housing: Grey, Tail: Grey)

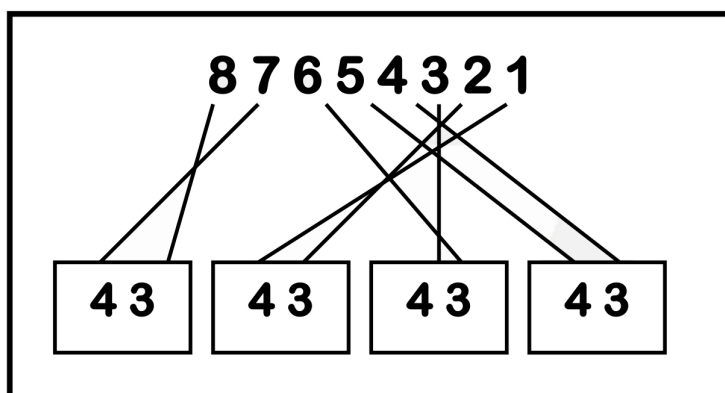

ADQ88 (Housing: Grey, Tail: Grey)

