

60 WATT CONSTANT VOLTAGE LED DRIVER



STONTRONICS: PAX2460TD

Features:

- Constant Voltage Output
- IP44 Rated
- Class II
- Compact Plastic Low Profile enclosure
- 2 Year Warranty



Description:

The Stontronics Range of 60 Watt Constant Voltage LED Drivers are housed in a compact light weight high quality IP44 plastic enclosure with covered input & output terminals suitable for general Indoor LED applications

Specification	
Part Number	PAX2460TD
Output Voltage Rating	24Vdc
Output Current Range	2.5A
Rated Power	60 Watt
Dimensions	170 x 50 x 31mm
Input Voltage Range	180V ~ 240VAC
Input Voltage Frequency	50-60Hz
Input power	<0.95W
Efficiency	>80%
Over Load Protection	Auto-recovery
Short Circuit Protection	Auto-recovery
Over Voltage Protection	Auto-recovery
Automatically Restart	Yes
Operating Temperature	-30°C ~ +45°C
Storage Temperature	-40°C ~ +70°C
Relative Humidity	5% to 95%
MTBF	50K hr
EMI Standard	Meets Emissions to EN55022, EN55015 Class B
Safety Standards	Design refers to EN60598, EN61547, ENV5024, EN61000-4-2, 3, 4, 6, 8,11, EN61000-3-2, EN61000-3-3


General Note
TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.

TT Electronics | Stontronics Ltd
Chancerygate Business Centre, Cradock Road, Reading RG2 0AH, UK
t: +44 (0) 118 931 1199

60 WATT CONSTANT VOLTAGE LED DRIVER

STONTRONICS: PAX2460TD

Diagrams

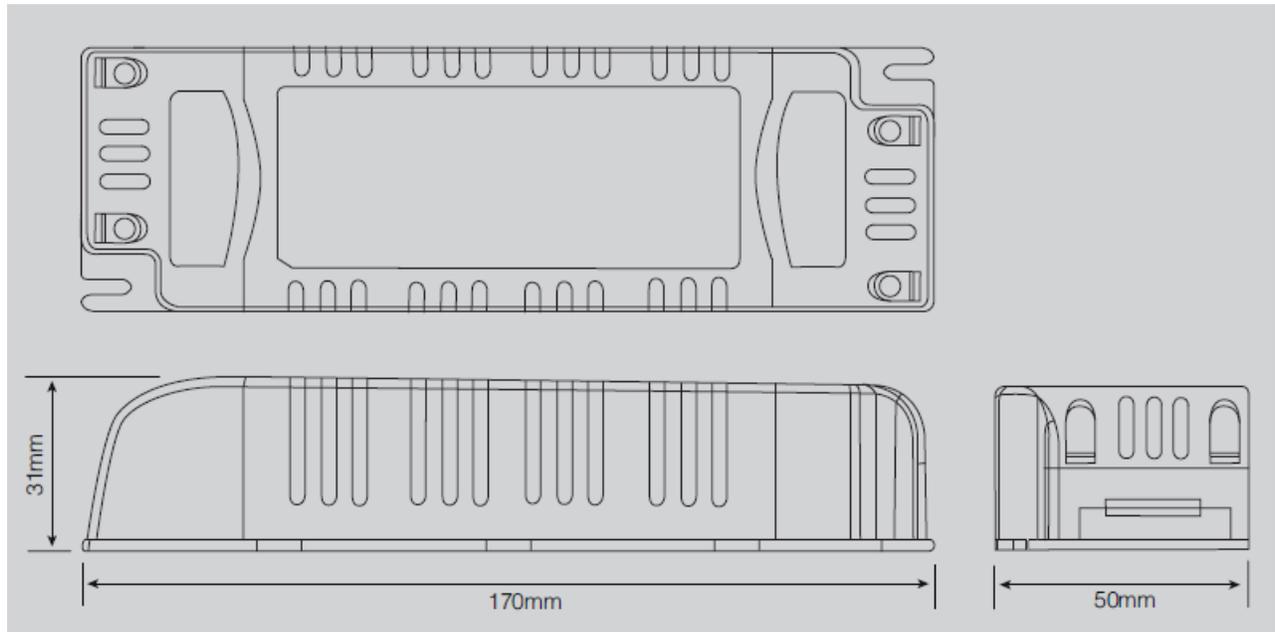

LED Configuration

