

Product information

13 05 160 T

Electricians' Pliers



- Pliers with tether attachment point for mounting a fall protection system
- The ideal pliers for cable work
- For gripping and bending wire
- For cutting medium hard and hard wire
- Precision cutting edges additionally induction-hardened, cutting edge hardness approx. 60 HRC
- With precision stripping holes
- For crimping wire ferrules
- Vanadium electric steel, forged, multi stage oil-hardened

General

Article No.	13 05 160 T
EAN	4003773079965
Pliers	chrome-plated
Head	chrome-plated
Handles	with multi-component grips, with integrated tether attachment point for a tool tether
Weight	142 g
Dimensions	160 x 59 x 20 mm
Reach	no
RohS	no


Technical details

Cutting capacities medium hard wire (diameter)	Ø 2.5
Cutting capacities hard wire (diameter)	Ø 1.6
Stripping capacities in square millimetres	0.5 — 0.75 / 1.5 / 2.5 mm ²
Drop Protection System	yes


Classification

eCl@ss 5.1.4	21040302
ETIM 5.0	EC000163
ETIM 6.0	EC000163
proficl@ss 6.0	AAA002c003
UNSPSC 13.1	27112148


technical change and errors excepted

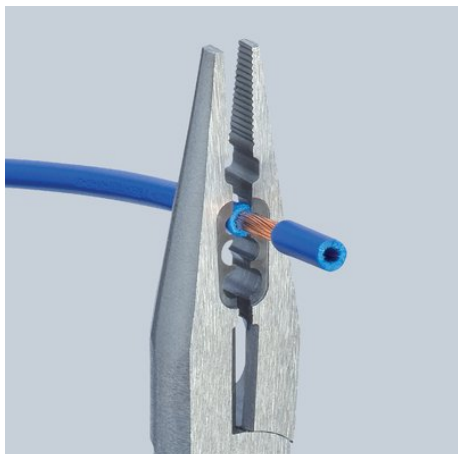


Stripping

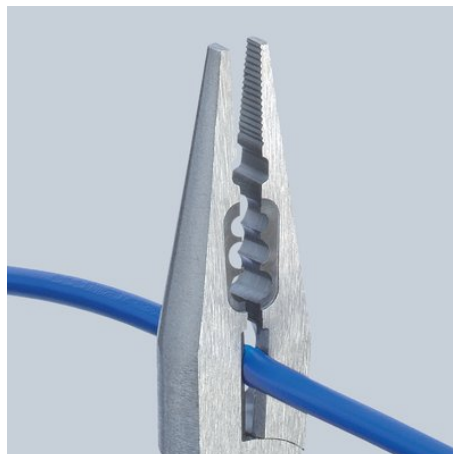

Cutting Edges

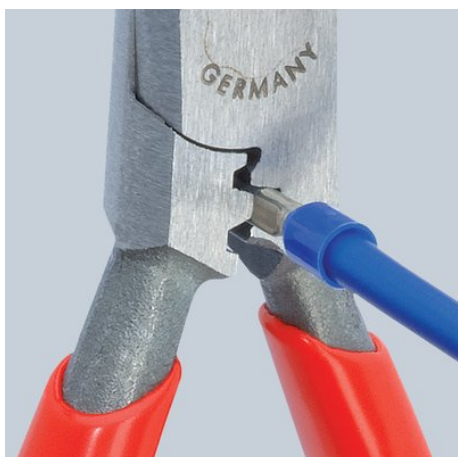

Crimping 0.5 to 2.5 mm²

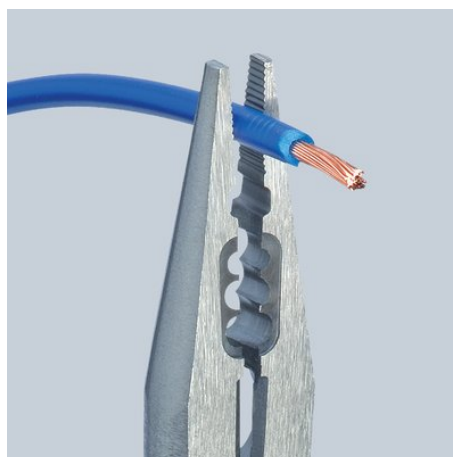

Gripping