

Product information

26 12 200 T

Snipe Nose Side Cutting Pliers (Stork Beak Pliers)

DIN ISO 5745

- Elastic tips: dimensionally stable even when twisted
- Pliers with tether attachment point for mounting a fall protection system
- Distortion-tolerant, elastic precision tips
- Half-round, long, tapered jaws
- With cutting edges for soft, medium-hard and hard wire
- Cutting edges additionally induction-hardened, cutting edge hardness approx. 61 HRC
- Vanadium electric steel, forged, multi stage oil-hardened




General

Article No.	26 12 200 T
EAN	4003773079989
Pliers	black atramentized
Head	polished
Handles	with multi-component grips, with integrated tether attachment point for a tool tether
Weight	200 g
Dimensions	200 x 57 x 20 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

Technical details

Cutting capacities medium hard wire (diameter)	Ø 3.2 mm
Cutting capacities hard wire (diameter)	Ø 2.2 mm
Jaw thickness (joint) (T1)	9.5 mm
Tips width (W4)	3.0 mm
Tips thickness (T2)	2.5 mm
Jaw length (L3)	73.0 mm
Head width (W3)	18 mm
Drop Protection System	yes

Technical details

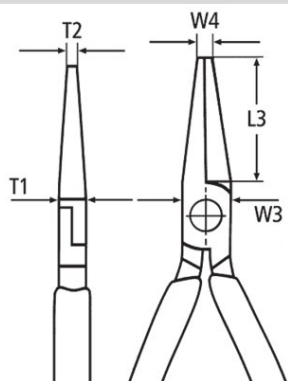

Classification

eCl@ss 5.1.4	21040301
proficl@ss 6.0	EAC420c044
UNSPSC 13.1	27112134

technical change and errors excepted

