

Product information

30 16 160

Long Nose Pliers

DIN ISO 5745 IEC 60900 DIN EN 60900

- Heavy duty and wear resisting
- Different jaw styles
- Long, trapezoidal jaws
- Chrome vanadium electric steel, forged, oil-hardened




General

Article No.	30 16 160
EAN	4003773001904
Pliers	chrome-plated
Head	chrome-plated
Handles	insulated with multi-component grips, VDE-tested
Weight	150 g
Dimensions	160 x 57 x 18 mm
Standard	DIN ISO 5745 DIN EN 60900 IEC 60900
Reach	no
RohS	no

Technical details

Jaw thickness (joint) (T1)	9.5 mm
Tips width (W4)	3.0 mm
Tips thickness (T2)	5.0 mm
Jaw length (L3)	46.5 mm
Head width (W3)	16.5 mm

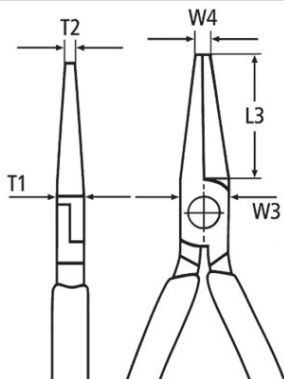

Classification

eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112134

technical change and errors excepted