

## Product information

# 32 31 135


## Relay Adjusting Pliers

- For gripping components and wires of the smallest diameters and for bending contact and relay springs
- Polished gripping surfaces
- Edges carefully deburred
- 40° bent, flat, concave and trapezoidal jaws
- High-grade special tool steel, forged, oil-hardened



General	
Article No.	32 31 135
EAN	4003773043560
Pliers	black atramentized
Head	polished
Handles	plastic coated
Weight	73 g
Dimensions	135 x 52 x 14 mm
Reach	no
RohS	no

Technical details	
Jaw thickness (joint) (D)	7.0 mm
Tips width (E)	1.0 mm
Tips thickness (F)	3.5 mm
Jaw length (B)	32.0 mm
Head width (A)	12.5 mm

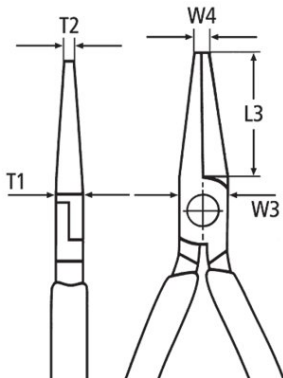

Classification	
eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA010c003
UNSPSC 13.1	27112104

technical change and errors excepted