

Product information

37 21 125

Flat Nose Pliers

For precision mechanics

DIN ISO 9655

- Precision pliers for fine assembly work, e.g. in electronics and fine mechanics
- For gripping, holding, bending and adjusting
- Tips precision-ground
- Smooth gripping surfaces
- Edges carefully deburred
- Lap joint
- Flat, concave and pointed jaws
- High-grade special tool steel, forged, oil-hardened




General

Article No.	37 21 125
EAN	4003773035138
Pliers	black atramentized
Head	polished
Handles	plastic coated
Weight	74 g
Dimensions	125 x 56 x 13 mm
Standard	DIN ISO 9655
Reach	no
RohS	no

Technical details

Jaw thickness (joint) (D)	7.0 mm
Tips width (E)	2.0 mm
Tips thickness (F)	2.0 mm
Jaw length (B)	27.0 mm
Head width (A)	12.5 mm

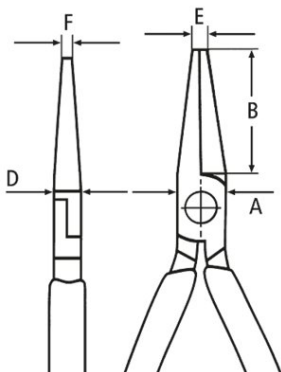

Classification

eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112104

technical change and errors excepted