

Product information

71 01 160

KNIPEX CoBolt® S

Compact Bolt Cutters



Small giant with 25-fold manual force amplification

- Extremely high cutting performance in a convenient length of 160 mm
- Small, slim head for excellent accessibility
- Compact and powerful: cuts bolts, nails, rivets etc. up to Ø 4.4 mm
- Heavy duty, induction-hardened cutting edge for thin, hard wire, screws and springs. Cutting edge hardness approx. 64 HRC
- Less physical effort due to efficient lever action mechanism
- No slipping of the material to be cut due to lasered cutting edge
- With gripping surface below the joint for gripping and pulling wires from Ø 1.0 mm
- Chrome vanadium heavy-duty steel, forged, multi stage oil-hardened



General

Article No.	71 01 160
EAN	4003773082668
Pliers	black atramentized
Handles	plastic coated
Weight	200 g
Dimensions	160 x 45 x 14 mm
Reach	no
RohS	no

Technical details

Cutting capacities soft wire (diameter)	Ø 5.3 mm
Cutting capacities medium hard wire (diameter)	Ø 4.4 mm
Cutting capacities hard wire (diameter)	Ø 3.2 mm
Cutting capacities piano wire (diameter)	Ø 3.0 mm

Classification

eCl@ss 5.1.4	21040302
ETIM 5.0	EC000165
ETIM 6.0	EC000165
proficl@ss 6.0	AAA949c004
UNSPSC 13.1	27111512



technical change and errors excepted



Compact, light and always to hand



Powerful through to the tips

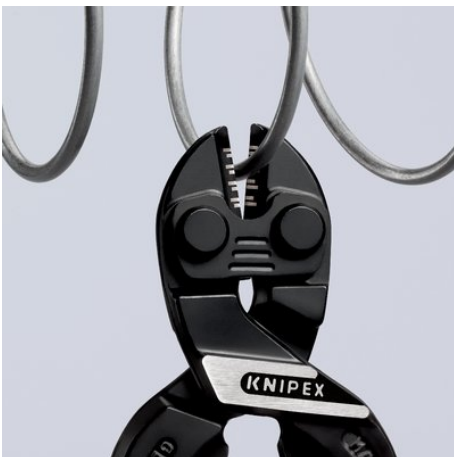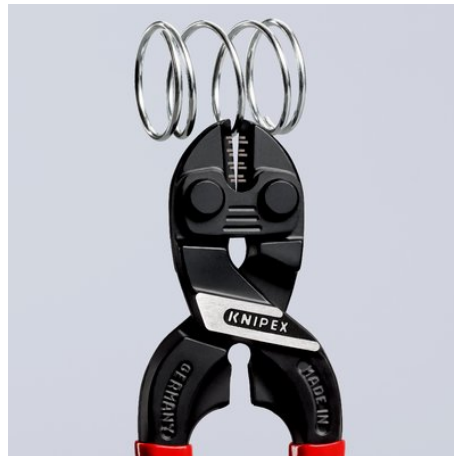



Slim head for ideal accessibility

