

Product information

86 03 150

Pliers Wrench

Pliers and a wrench in a single tool



- Replaces the need for sets of metric and imperial spanners
- Smooth jaws for damage free installation of plated fittings - working directly on chrome!
- Also excellent for gripping, holding, pressing and bending workpieces
- Zero backlash jaw pressure prevents damage to edges of sensitive components
- Push the button for adjustment on the workpiece
- No unintentional shift of the gripping jaws and no slipping of the joint
- Parallel jaws give a more solid grip; its design allows flexible adjustment of all widths up to the specified maximum size
- The ratchet type principle allows quick and easy tightening and release of all bolted connections
- Lever transmission greater than 10 : 1 for strong gripping power
- Chrome vanadium electric steel, forged, oil-hardened




General

Article No.	86 03 150
EAN	4003773069676
Pliers	chrome-plated
Head	chrome-plated
Handles	plastic coated
Weight	175 g
Dimensions	150 x 50 x 25 mm
Reach	no
RohS	no

Technical details

Jaw thickness (joint) (B2)	7.0 mm
Joint thickness (B3)	10.5 mm
Tips thickness (B1)	4.7 mm
Adjustment positions	14
Capacities for nuts	Ø 1 Inch
Capacities for nuts	27 mm

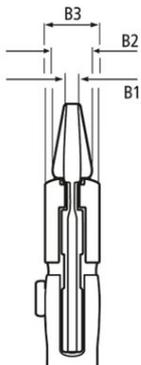

Classification

eCl@ss 5.1.4	21043826
proficl@ss 6.0	AAA936c004
UNSPSC 13.1	27112112


Spare Parts

86 09 150	Range of spare parts adjustment for 86 150,
-----------	---

technical change and errors excepted



replaces the need for sets of metric and imperial spanners

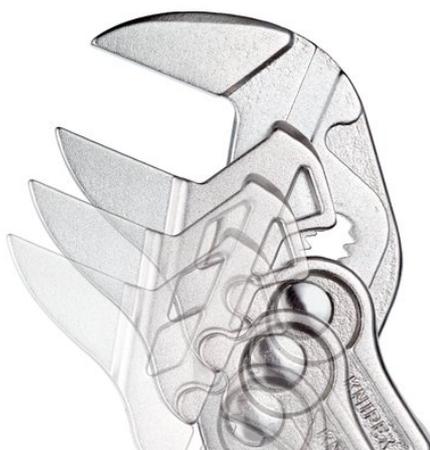



Fast adjustment at the touch of a button