

## Product information

# 86 03 300

## Pliers Wrench

Pliers and a wrench in a single tool



- Replaces the need for sets of metric and imperial spanners
- Smooth jaws for damage free installation of plated fittings - working directly on chrome!
- Also excellent for gripping, holding, pressing and bending workpieces
- Zero backlash jaw pressure prevents damage to edges of sensitive components
- Fast adjustment by pushing a button directly on the workpiece
- No unintentional shift of the gripping jaws and no slipping of the joint
- Parallel jaws give a more solid grip; its design allows flexible adjustment of all widths up to the specified maximum size
- The ratchet type principle allows quick and easy tightening and release of all bolted connections
- Lever transmission greater than 10 : 1 for strong gripping power
- Chrome vanadium electric steel, forged, oil-hardened




### General

Article No.	86 03 300
EAN	4003773041429
Pliers	chrome-plated
Head	chrome-plated
Handles	plastic coated
Weight	656 g
Dimensions	300 x 75 x 20 mm
Reach	no
RohS	no

### Technical details

Jaw thickness (joint) (B2)	9.5 mm
Joint thickness (B3)	15.0 mm
Tips thickness (B1)	9.5 mm
Adjustment positions	24
Capacities for nuts	Ø 2 1/2 Inch
Capacities for nuts	68 mm

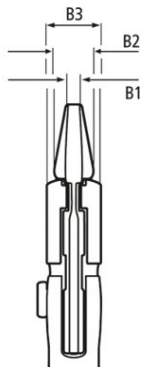

### Classification

eCl@ss 5.1.4	21043826
proficl@ss 6.0	AAA936c004
UNSPSC 13.1	27112112

## Spare Parts

87 09 01

Assortment of spare parts for adjustment for 86/87 XX 250/300  
(without 87 2X XXX),

*technical change and errors excepted*

