

Product information

86 05 180

Pliers Wrench

Pliers and a wrench in a single tool




- Replaces the need for sets of metric and imperial spanners
- Smooth jaws for damage free installation of plated fittings - working directly on chrome!
- Also excellent for gripping, holding, pressing and bending workpieces
- Zero backlash jaw pressure prevents damage to edges of sensitive components
- Fast adjustment by pushing a button directly on the workpiece
- No unintentional shift of the gripping jaws and no slipping of the joint
- Parallel jaws give a more solid grip; its design allows flexible adjustment of all widths up to the specified maximum size
- The ratchet type principle allows quick and easy tightening and release of all bolted connections
- Lever transmission greater than 10 : 1 for strong gripping power
- Chrome vanadium electric steel, forged, oil-hardened



General	
Article No.	86 05 180
EAN	4003773047162
Pliers	chrome-plated
Head	chrome-plated
Handles	with multi-component grips
Weight	260 g
Dimensions	180 x 55 x 20 mm
Reach	no
RohS	no

Technical details	
Jaw thickness (joint) (B2)	8.0 mm
Joint thickness (B3)	12.0 mm
Tips thickness (B1)	5.0 mm
Adjustment positions	15
Capacities for nuts	Ø 1 1/2 Inch
Capacities for nuts	40 mm

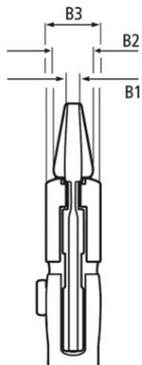

Classification

eCl@ss 5.1.4	21043826
proficl@ss 6.0	AAA936c004
UNSPSC 13.1	27112112

Spare Parts

86 09 180	Range of spare parts adjustment for 86 XX 180,
-----------	--

technical change and errors excepted

