

Product information

86 43 250

Pliers Wrench

Pliers and a wrench in a single tool



- Replaces the need for sets of metric and imperial spanners
- Smooth jaws for damage free installation of plated fittings - working directly on chrome!
- 15° angled pliers handle provides space for counter screw connections or bolted fittings on surfaces
- Reduced risk of knuckle injuries
- Also excellent for gripping, holding, pressing and bending workpieces
- Zero backlash jaw pressure prevents damage to edges of sensitive components
- Fast adjustment by pushing a button directly on the workpiece
- No unintentional shift of the gripping jaws and no slipping of the joint
- Parallel jaws give a more solid grip; its design allows flexible adjustment of all widths up to the specified maximum size
- The ratchet type principle allows quick and easy tightening and release of all bolted connections
- Lever transmission greater than 10 : 1 for strong gripping power
- Chrome vanadium electric steel, forged, oil-hardened




General

Article No.	86 43 250
EAN	4003773081296
Pliers	chrome-plated
Head	chrome-plated
Handles	plastic coated
Weight	535 g
Dimensions	250 x 50 x 34 mm
Reach	no
RohS	no

Technical details

Jaw thickness (joint) (B2)	8.0 mm
Joint thickness (B3)	14.0 mm
Tips thickness (B1)	8.0 mm
Adjustment positions	17
Capacities for nuts	Ø 1 3/4 Inch
Capacities for nuts	46 mm

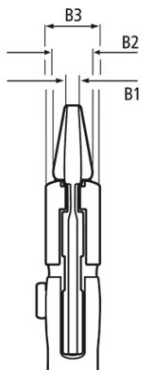

Classification

eCl@ss 5.1.4	21043826
proficl@ss 6.0	AAA936c004
UNSPSC 13.1	27112112


Accessories

86 09 250 V01	Protective jaws for 86 XX 250, 3 pairs
---------------	--

Spare Parts

87 09 01	Assortment of spare parts for adjustment for 86/87 XX 250/300 (without 87 2X XXX),
----------	--

technical change and errors excepted

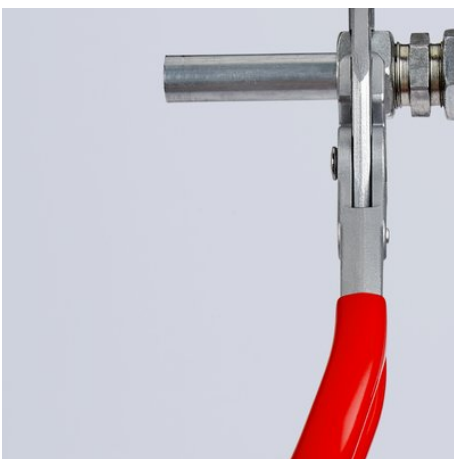

Angled handles for more room to grip