

Product information

90 22 02 SB

KNIPEX TwistCut® Corrugated Pipe Cutter



Fast and safe cutting of corrugated plastic pipes

- For the reliable and fast cutting of many plastic corrugated pipes with the universal capacity range from Ø 13 to 32 mm
- For corrugated plastic pipes with ridge widths of up to 2.7 mm
- No damage to the internal cables or pipes
- Separate even softer, flexible plastic corrugated pipes: Apply little pressure on the TwistCut® when cutting to avoid the corrugated pipe to be deformed
- With stripping blades for cross-sections 0.2 / 0.3 / 0.8 / 1.5 / 2.5 / 4.0 mm²
- Location ridges (patent pending) on the 1.5 and 2.5 mm² wire stripping blades for the fast insertion of cable
- Internal length scale for consistent stripping of cable, legible for both right and left handed users
- Simple insertion, reliable and easy cutting without waste
- Precise cut without damage thanks to unique arrangement of the cutters with side guide
- Good accessibility thanks to slim design
- Made of glass fibre reinforced multi-component plastic with soft gripping zone

General

Article No.	90 22 02 SB
EAN	4003773082293
Weight	47 g
Dimensions	100 x 86 x 38 mm
Reach	no
RohS	no


Technical details

Cutting capacities (diameter)	Ø 13 – 32 mm
Wire stripping value for conductors and strands	0.2 – 4 mm ²

Classification

eCl@ss 5.1.4	21040601
ETIM 5.0	EC000148
ETIM 6.0	EC000148
proficl@ss 6.0	AAB927c006
UNSPSC 13.1	23151901

technical change and errors excepted

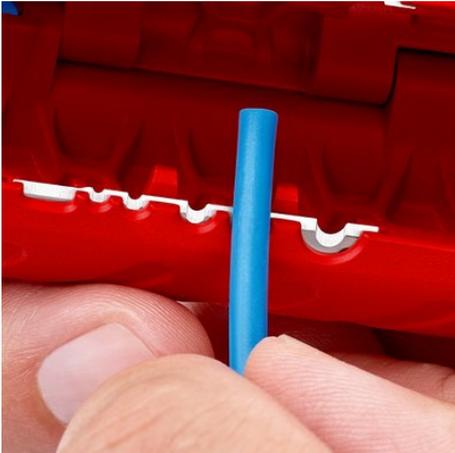

90 22 02 SB: Practical locator simplifies the insertion of single conductors for stripping



90 22 02 SB: Injection moulded length scale for consistent stripping to a uniform length, legible for left and right handed users





