 


Product information

97 32 240

- With threaded holes for cutting copper and brass screws threaded M 2.6 / M 3 / M 3.5 / M 4 and M 5
- Bolted joint for higher stability and even movement
- Special steel, high-strength

Crimping Pliers



General	
Article No.	97 32 240
EAN	4003773079491
Pliers	black lacquered
Handles	with multi-component grips
Weight	264 g
Dimensions	240 x 62 x 25 mm
Reach	no
RohS	no

Technical details



Applications	insulated terminals + cable connectors
Capacity in square millimetres	0.5 — 6.0 mm ²
Number of crimping positions	3
AWG	20 — 10




Applications	non-insulated terminals + cable connectors
Capacity in square millimetres	0.5 — 6.0 mm ²
Number of crimping positions	3
AWG	20 — 10


Classification

eCl@ss 5.1.4	21040301
ETIM 5.0	EC000168
ETIM 6.0	EC000168
proficl@ss 6.0	AAA946c003
UNSPSC 13.1	27112147

technical change and errors excepted

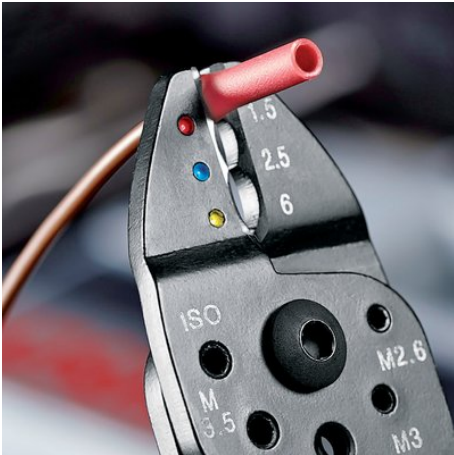


97 21 215

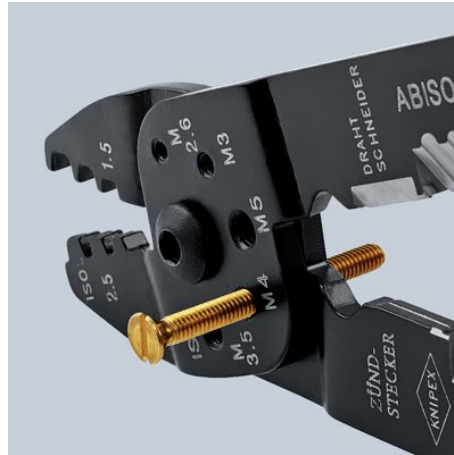

97 21 215 B



97 21 215 B

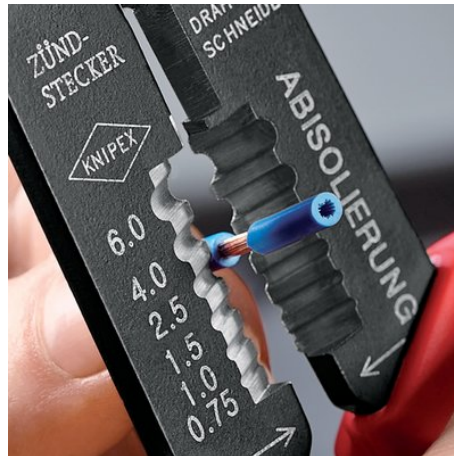

97 21 215 B



97 21 215 B