

KNIPEX Quality – Made in Germany



Set of Circlip Pliers

4 and 8 parts

In practical tool roll:
space-saving,
protected, organised



Set of Circlip Pliers

4 and 8 parts

00
19

- > Tool roll made of hard-wearing polyester fabric
- > With practical, adjustable quick release fastener

00 19 56

Four common Circlip Pliers for internal and external circlips




00 19 57

Four common Precision Circlip Pliers for highest requirements



Article No.	EAN			Style	Capacity Ø mm	Tips Ø mm	Quantity	g
00 19 56 V01	4003773-081548		Set of Circlip Pliers, 4 parts					615
		⊙	44 11 J1	straight tips	12 - 25	1,3	1	
		⊙	44 11 J2		19 - 60	1,8	1	
		⊙ MM	46 11 A1		10 - 25	1,3	1	
		⊙ MM	46 11 A2		19 - 60	1,8	1	
00 19 57 V01	081555		Precision Circlip Pliers Set 4 parts					871
		⊙	48 11 J2	straight tips	19 - 60	1,3	1	
		⊙ 90°	48 21 J21	angled tips	19 - 60	1,8	1	
		⊙ MM	49 11 A2	straight tips	19 - 60	1,3	1	
		⊙ 90° MM	49 21 A21	angled tips	19 - 60	1,8	1	

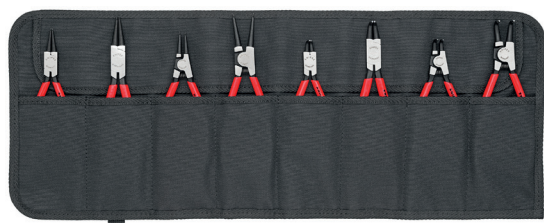

00 19 58 V01

Eight established models of circlip pliers for internal and external circlips



00 19 58 V02

Eight established models of precision circlip pliers for the most demanding requirements

Article No.	EAN			Style	Capacity Ø mm	Tips Ø mm	Quantity	g
00 19 58 V01	4003773-081562		Set of Circlip Pliers, 8 parts					1156
		⊙	44 11 J1	straight tips	12 - 25	1.3	1	
		⊙	44 11 J2		19 - 60	1.8	1	
		⊙ 90°	44 21 J11	angled tips	12 - 25	1.3	1	
		⊙ 90°	44 21 J21		19 - 60	1.8	1	
		⊙ MM	46 11 A1	straight tips	10 - 25	1.3	1	
		⊙ MM	46 11 A2		19 - 60	1.8	1	
		⊙ 90° MM	46 21 A11	angled tips	10 - 25	1.3	1	
		⊙ 90° MM	46 21 A21		19 - 60	1.8	1	
00 19 58 V02	081579		Precision Circlip Pliers Set, 8-parts					1357
		⊙ MM	48 11 J1	straight tips	12 - 25	1.3	1	
		⊙ MM	48 11 J2		19 - 60	1.8	1	
		⊙ 90° MM	48 21 J11	angled tips	12 - 25	1.3	1	
		⊙ 90° MM	48 21 J21		19 - 60	1.8	1	
		⊙ MM	49 11 A1	straight tips	10 - 25	1.3	1	
		⊙ MM	49 11 A2		19 - 60	1.8	1	
		⊙ 90° MM	49 21 A11	angled tips	10 - 25	1.3	1	
		⊙ 90° MM	49 21 A21		19 - 60	1.8	1	