

KNIPEX Quality – Made in Germany



KNIPEX CoBolt® S

Compact and powerful

Now in a handy length of 160 mm

Strong cutting edges:
specially hardened and
laser-cut

Structured gripping
surface for gripping and
pulling securely

Strongest cutters of
their length thanks to
high leverage joint






KNIPEX CoBolt® S
Compact Bolt Cutter

71

- ▶ Extremely high cutting performance in a convenient length of 160 mm
- ▶ Small, slim head for excellent accessibility
- > Compact and powerful: cuts bolts, nails, rivets etc. up to a diameter of 4.4 mm
- > Heavy duty, induction hardened cutting edge for thin, hard wire, screws and springs. Cutting edge hardness approx. 64 HRC
- > Less physical effort due to efficient lever action mechanism
- > No slipping of the material to be cut due to lasered cutting edge
- > With gripping surface below the joint for gripping and pulling wires with a diameter from as Ø 1.0 mm
- > Chrome vanadium heavy-duty steel, forged, multi stage oil-hardened

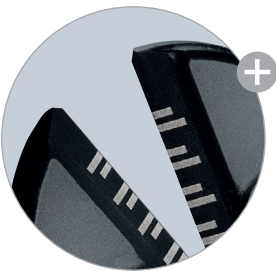

Lasered cutting edge prevents the material to be cut from slipping

Product video



Our CoBolt® family:



71 01 160
High cutting force with a length of just 160 mm – ideal for small hands



71 01 200
200 mm long, the classic among the compact bolt cutters



71 01 250
Also for two-hand operation: the 250 mm long KNIPEX CoBolt® XL cuts piano wire up to Ø 4.2 mm



Powerful through to the tips



Slim head for ideal accessibility



Compact, light and always to hand

Article No.	EAN 4003773-	↔ mm		Pliers	Handles	Cutting capacities				g
						Ø mm	Ø mm	Ø mm	Ø mm	
71 01 160	082668	160	✂	black atramentized	plastic coated	5.3	4.4	3.2	3.0	195
71 01 200	033165	200	✂	black atramentized	plastic coated	6.0	5.2	4.0	3.6	335
71 01 250	079637	250	✂	black atramentized	plastic coated		5.6	4.0	3.8	465