


KNIPEX Quality – Made in Germany




KNIPEX TwinGrip – Slip Joint Pliers

**Front or sideways –
they grab them all**

Flexible. Handy. Strong.

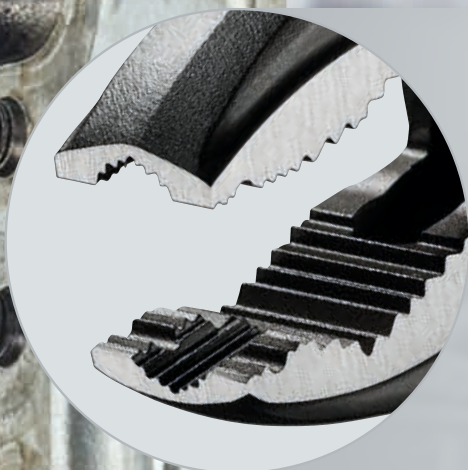

 Toothed gripping surfaces
along the longitudinal axis of
the pliers make it possible to
grip worn bolts and screws
tightly from the front



KNIPEX TwinGrip Slip Joint Pliers

from 09.2021

The all-purpose solution for stuck workpieces, such as bolts and screws


- ▶ Unique combination: Front grip and side grip function, box joint, push button adjustment
- ▶ Very slim pliers let you work even in confined installation spaces with a narrow turning zone for fast results
- ▶ High-grip front jaw with robust teeth and high gear ratio at the tip of the mouth
- ▶ Large front and side gripping capacity for diameters and widths across flats 4 - 22 mm
- ▶ Reliable front gripping of flat workpieces due to the three-point system
- ▶ Gripping, tightening and loosening screws with worn heads and threads
- ▶ Five-way adjustable slip joint with push button adjustment for precise adjustment of gripping capacity
- ▶ Pinch stop reduces the risk of crushed fingers
- ▶ Durable and resilient due to the robust box joint
- ▶ Forged from high-grade chrome vanadium electric steel, oil-hardened, teeth additionally induction-hardened to approx. 61 HRC



82 01 200



82 02 200

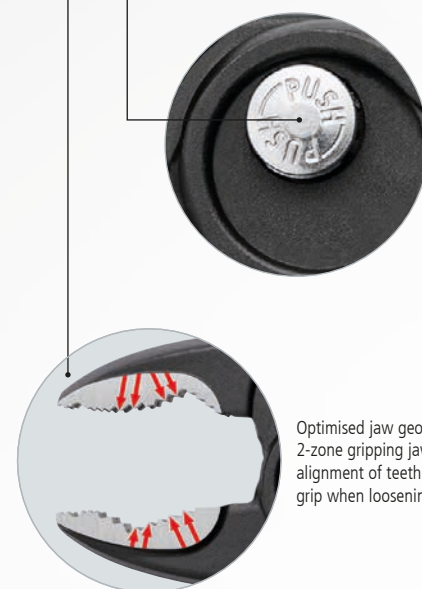

Comfortable and reliable:
The push button adjusts the gripping capacity in five steps directly on the workpiece and then locks securely – no accidental loss of adjustment!

Optimised jaw geometry:
2-zone gripping jaw with opposing alignment of teeth – for maximum grip when loosening and tightening.



The KNIPEX TwinGrip allows the gripping capacity to be set flexibly in five positions...



...and the position to be changed quickly at the touch of a button!



The box joint is robust and flexible, so that the pliers can hold workpieces between 4 and 22 mm in place.

Article no.	EAN 4003773-	mm	Pliers	Head	Handles	Adjustment positions	Ø Inch	Ø mm	Inch	mm	g
82 01 200	N 087243	200	black atramentized	polished	with non-slip plastic coating	5	5/32 - 7/8	4 - 22	5/32 - 7/8	4 - 22	270
82 01 200 SB	N 087571	200				5	5/32 - 7/8	4 - 22	5/32 - 7/8	4 - 22	270
82 02 200	N 087250	200			with multi-component grips	5	5/32 - 7/8	4 - 22	5/32 - 7/8	4 - 22	280
82 02 200 SB	N 087588	200				5	5/32 - 7/8	4 - 22	5/32 - 7/8	4 - 22	280