

KNIPEX Quality – Made in Germany



KNIPEX TwistCut

Corrugated Pipe Cutter

For plastic corrugated pipes
from Ø 13 mm to Ø 32 mm

With soft multi-
component grip zone

Transport safely
thanks to catch

Precision ground adapted
blades for wire stripping

Cuts quickly, cleanly
and reliably

www.knipex.com



KNIPEX TwistCut

Corrugated Pipe Cutter

90

(PAT. PEND.)


- For the reliable and fast cutting of plastic corrugated pipes with the universal capacity range of diameters from 13 to 32 mm
- No damage to the internal cables or pipes

- > Simple insertion, reliable and easy cutting without waste
- > Precise cut without damage thanks to unique arrangement of the cutters with side guide
- > Good accessibility thanks to slim design
- > Made of glass fibre reinforced multi-component plastic with soft gripping zone

90 22 02 SB


- > With wire stripping blades for diameters of 0.2/0.3/0.8/1.5/2.5/4.0 mm
- > Location ridges (patent pending) on the 1.5 and 2.5 mm² wire stripping blades for the fast insertion of cable
- > Internal length scale for consistent stripping of cable, legible for both right and left handed users

90 22 01 SB
Without stripping
function

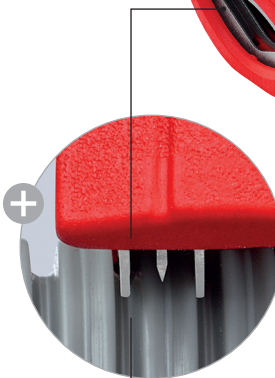

Internal blades with lateral guide
to protect against injuries

90 22 02 SB
With stripping function

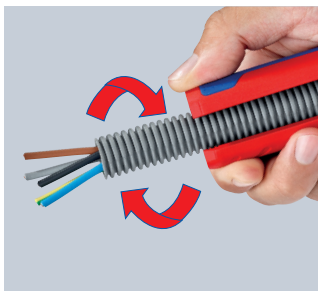

Easy to use: press KNIPEX TwistCut together, turn with slight pressure, done




Also for protective pipes on aluminium composite pipes in plumbing, up to a diameter of 32 mm

Product video



Clean cutting edge with no damage to internal cables as the cut is always at the top of the corrugation

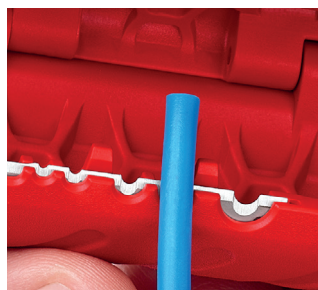

90 22 02 SB: Practical locator simplifies the insertion of single conductors for stripping



Convenient handling due to fastener with locking device and opening by means of internal spring



90 22 02 SB: Injection moulded length scale for consistent stripping to a uniform length, legible for left and right handed users

Article No.	EAN	↔ mm	Corrugated pipe cutting performance Ø mm	Stripping capacities mm ²	⚖
90 22 01 SB	082286	100	13 - 32		9
90 22 02 SB	082293	100	13 - 32	0.2 - 4.0	47