

KNIPEX Quality – Made in Germany



Screwdrivers "Slim"

for PlusMinus profile screws

Smooth transition to
the insulated shaft

Smooth transition to
the insulated shaft


Streamlined insulation
for perfect accessibility



Screwdrivers "Slim" for PlusMinus profile screws

98

- ▶ With the "Slim" version of the screwdriver, sunken screws with PlusMinus profile can also be reached easily
- ▶ The integrated blade insulation permits unhindered access while insulation values remain consistent
 - > Use with electrical installation components such as circuit breakers
 - > Driving tips for PlusMinus screws
 - > Ergonomically optimised dual component handle design that prevents rolling; for reduced fatigue and optimised transmission of force
 - > Chrome vanadium molybdenum steel

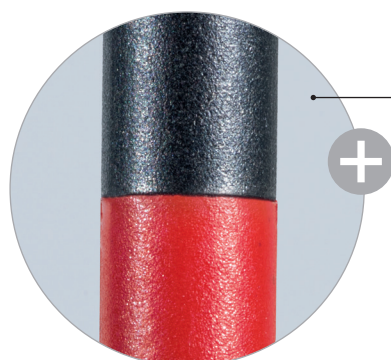

Smooth transition to the insulated shaft



98 24 01 SLS



98 24 02 SLS



98 25 01 SLS




98 25 02 SLS



98 24 01 SLS: Phillips®/slotted



98 24 02 SLS: Phillips®/slotted

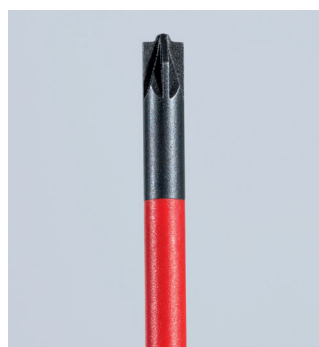

98 25 01 SLS: Pozidriv®/slotted



98 25 02 SLS: Pozidriv®/slotted

Article No.	EAN 4003773-	↔ mm		Description	Blade length mm	Length of non-insulated blade mm	Handle length mm	⚖ g
98 24 01 SLS	081036	187	⚡ 1000 V	burnished, insulated with multi-component grips, VDE-tested	80	15	107	56
98 24 02 SLS	081043	212	⚡ 1000 V		100	18	112	90
98 25 01 SLS	081050	187	⚡ 1000 V		80	15	107	56
98 25 02 SLS	081067	212	⚡ 1000 V		100	18	118	90