


## MCE65 4M

**Order symbol:** MCE65 4M  
**Product nbr:** 7350000  
**EAN:** 6418074315700

**Description:**  
 Modular component enclosure IP65 including DIN rail, insulated terminals (neutral and earth), cover for unused modules, plastic cap for screws



DIMENSIONS AND SPECIFICATIONS		ACCESSORIES	Included
<b>Dimensions (HxWxD) mm:</b>	201 x 128 x 120	Cover for unused modules – grey	YES
<b>No. of modules/rows:</b>	4/1	Insulated terminal, standard	YES
<b>Nominal voltage:</b>	In 63A	Rubber grommets	Optional
<b>Rated voltage:</b>	AC 400V / DC 1000V	Lock for enclosure	Optional
<b>No. of terminals N/PE (6mm<sup>2</sup>):</b>	4/4		
<b>No. of knock-outs:</b>			
Top/bottom	2xM25/32		
Side	2xM20		
MATERIALS			
<b>Base:</b>	Acrylonitrile acrylic styrene		
<b>Base colour:</b>	RAL 7035		
<b>Cover:</b>	Polycarbonate		
<b>Cover colour:</b>	Transparent		
<b>Glow wire test:</b>	650°C		
<b>Terminal holder:</b>	Self-extinguishing		
RATING		TEMPERATURE	
<b>Ingress Protection:</b>	IP65	<b>Temperature °C (continuous):</b>	-25 ... +60 °C
<b>Impact Resistance:</b>	IK08		
<b>Certification according to:</b>	IEC 60670 / IEC 60228		

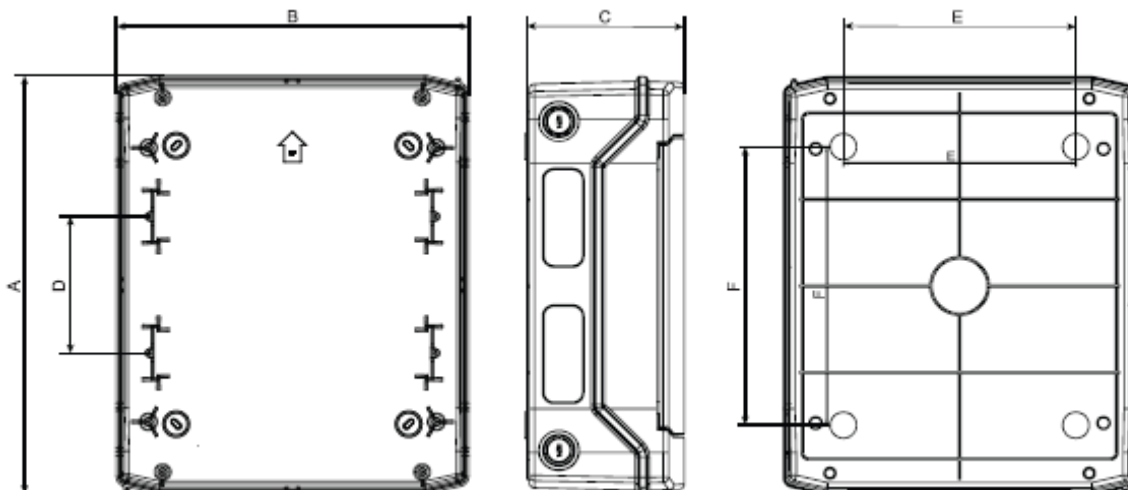

	A	B	C	D	E	F	Pde	Static load
MCE65 4M	201mm	128mm	120mm	-	-	140mm	10 W	0.65 kg
MCE65 6M	201mm	165mm	118mm	-	63mm	140mm	10 W	0.98 kg
MCE65 8M	201mm	202mm	120mm	-	100mm	140mm	13 W	1.30 kg
MCE65 12M	259mm	319mm	144mm	-	210mm	130mm	16 W	1.95 kg
MCE65 18M	259mm	428mm	144mm	-	259mm	130mm	20 W	2.93 kg
MCE65 24M	384mm	319mm	144mm	125mm	210mm	255mm	24 W	1.95 kg
MCE65 36M	535mm	319mm	144mm	125mm	210mm	380mm	26 W	1.95 kg
MCE65 48M	664mm	319mm	144mm	125mm	210mm	505mm	28 W	1.95 kg