

## MCE65 6M

**Order symbol:** MCE65 6M  
**Product nbr:** 7350001  
**EAN:** 6418074315717

**Description:**  
 Modular component enclosure IP65 including DIN rail, insulated terminals (neutral and earth), cover for unused modules, plastic cap for screws



### DIMENSIONS AND SPECIFICATIONS

<b>Dimensions (HxWxD) mm:</b>	201 x 165 x 120
<b>No. of modules/rows:</b>	6/1
<b>Nominal voltage:</b>	In 63A
<b>Rated voltage:</b>	AC 400V / DC 1000V
<b>No. of terminals N/PE (6mm<sup>2</sup>):</b>	6/6
<b>No. of knock-outs:</b>	
Top/bottom	1xM20/25+2xM12/20
Side	2xM20

### ACCESSORIES

ACCESSORIES	Included
Cover for unused modules – grey	YES
Insulated terminal, standard	YES
Rubber grommets	Optional
Lock for enclosure	Optional

### MATERIALS

<b>Base:</b>	Acrylonitrile acrylic styrene
<b>Base colour:</b>	RAL 7035
<b>Cover:</b>	Polycarbonate
<b>Cover colour:</b>	Transparent
<b>Glow wire test:</b>	650°C
<b>Terminal holder:</b>	Self-extinguishing


### RATING

<b>Ingress Protection:</b>	IP65
<b>Impact Resistance:</b>	IK08

**Certification according to:** IEC 60670 / IEC 60228

### TEMPERATURE

**Temperature °C (continuous):** -25 ... +60 °C

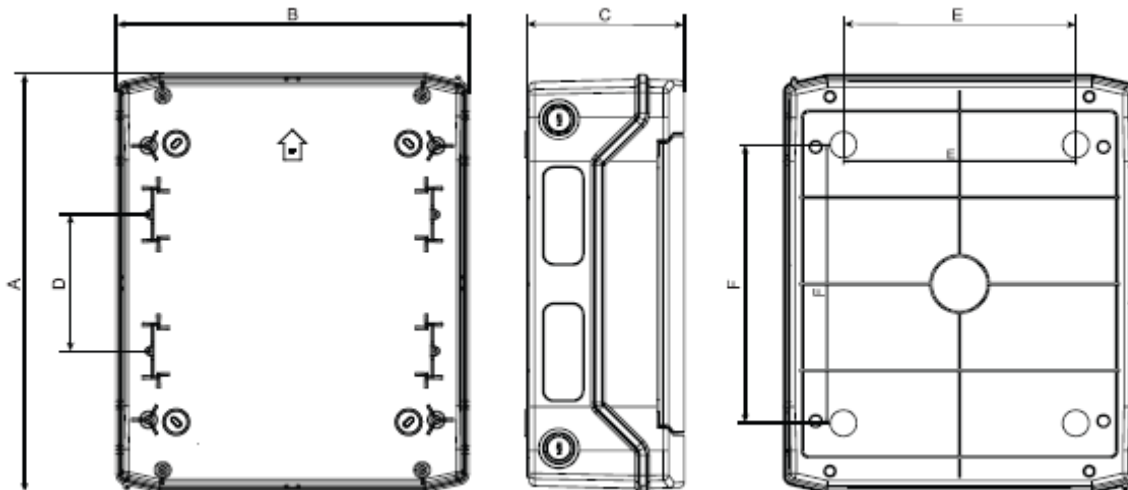

	A	B	C	D	E	F	Pde	Static load
MCE65 4M	201mm	128mm	120mm	-	-	140mm	10 W	0.65 kg
MCE65 6M	201mm	165mm	118mm	-	63mm	140mm	10 W	0.98 kg
MCE65 8M	201mm	202mm	120mm	-	100mm	140mm	13 W	1.30 kg
MCE65 12M	259mm	319mm	144mm	-	210mm	130mm	16 W	1.95 kg
MCE65 18M	259mm	428mm	144mm	-	259mm	130mm	20 W	2.93 kg
MCE65 24M	384mm	319mm	144mm	125mm	210mm	255mm	24 W	1.95 kg
MCE65 36M	535mm	319mm	144mm	125mm	210mm	380mm	26 W	1.95 kg
MCE65 48M	664mm	319mm	144mm	125mm	210mm	505mm	28 W	1.95 kg