

MCE65 8M

Order symbol: MCE65 8M
Product nbr: 7350002
EAN: 6418074315724

Description:
 Modular component enclosure IP65 including DIN rail, insulated terminals (neutral and earth), cover for unused modules, plastic cap for screws



DIMENSIONS AND SPECIFICATIONS

Dimensions (HxWxD) mm: 201 x 202 x 120
No. of modules/rows: 8/1
Nominal voltage: In 63A
Rated voltage: AC 400V / DC 1000V
No. of terminals N/PE (6mm²): 8/8
No. of knock-outs:
 Top/bottom 1xM25/32
 Side 2xM20

ACCESSORIES

Accessory	Included
Cover for unused modules – grey	YES
Insulated terminal, standard	YES
Rubber grommets	Optional
Lock for enclosure	Optional

MATERIALS

Base: Acrylonitrile acrylic styrene
Base colour: RAL 7035
Cover: Polycarbonate
Cover colour: Transparent
Glow wire test: 650°C
Terminal holder: Self-extinguishing


RATING

Ingress Protection: IP65
Impact Resistance: IK08

TEMPERATURE

Temperature °C (continuous): -25 ... +60 °C

Certification according to: IEC 60670 / IEC 60228

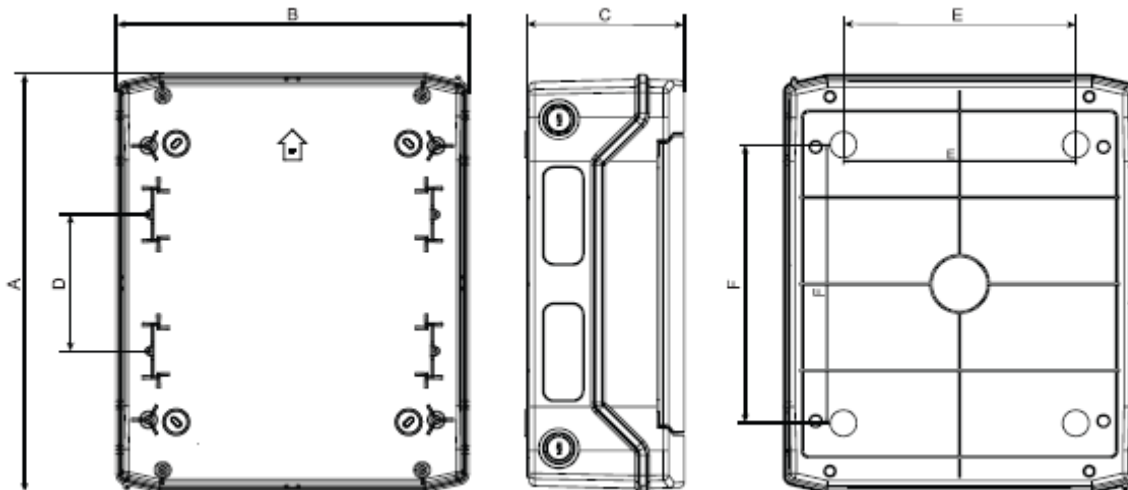

	A	B	C	D	E	F	Pde	Static load
MCE65 4M	201mm	128mm	120mm	-	-	140mm	10 W	0.65 kg
MCE65 6M	201mm	165mm	118mm	-	63mm	140mm	10 W	0.98 kg
MCE65 8M	201mm	202mm	120mm	-	100mm	140mm	13 W	1.30 kg
MCE65 12M	259mm	319mm	144mm	-	210mm	130mm	16 W	1.95 kg
MCE65 18M	259mm	428mm	144mm	-	259mm	130mm	20 W	2.93 kg
MCE65 24M	384mm	319mm	144mm	125mm	210mm	255mm	24 W	1.95 kg
MCE65 36M	535mm	319mm	144mm	125mm	210mm	380mm	26 W	1.95 kg
MCE65 48M	664mm	319mm	144mm	125mm	210mm	505mm	28 W	1.95 kg