



THE WORLD LEADER IN LADDERS™



3-in-1 Combination Ladder


7101318

*Versatile, multi-functional
model, with 3 positions
in 1 portable package*



Heavy Duty Box Section

Durable construction for regular use

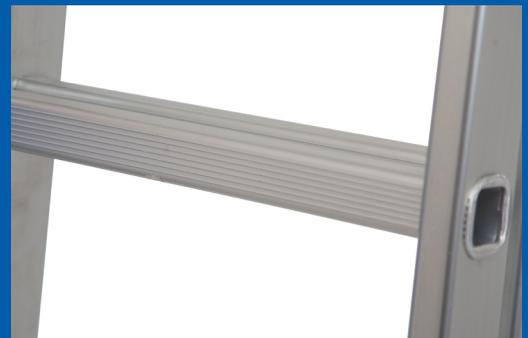

Slip-Resistant Rungs

for security



Wide Base Stabiliser

for stability and safety

IMPROVED DESIGN

Visit us online to see our
full line of ladders
www.wernerladder.co.uk



THE WORLD LEADER IN LADDERS™

7101318

3-in-1 Combination Ladder


150kg
MAX. LOAD
(Load includes user, tools, materials, etc)

Manufacturer's Guarantee
25 YEAR
Materials & Workmanship

Combines a stepladder, extension ladder, and a stairwell ladder all in one product



Heavy duty box section stiles for extra rigidity

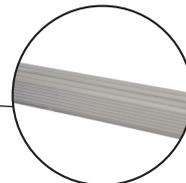

Slip-resistant square rungs for comfort and security



Unique sliding mechanism for easy conversion to 3 different positions



Locking restraint for added ladder stability when in use



Wide stabiliser bar for added safety when in use



EN131

Suitable for Professional & Non-professional use



SPECIFICATIONS

Product Code	Closed Length	Safe Working Height* <i>(in extension ladder mode)</i>	Safe Working Height* <i>(in stepladder mode)</i>	Safe Working Height* <i>(in stairwell mode)</i>	Weight
7101318	1.70m (5'7")	3.27m (10'8")	2.73m (8'11")	3.02m (9'10")	6.2kg

*Based on 1.75m (5'9") as the average reach height of a person.



APPROVED TO THE
NEW EN131 STANDARD
FOR PROFESSIONAL USE