

PHILIPS

Home projector

NeoPix Easy

LED LCD

Up to 80"

Built-in stereo speakers

NPX440



Don't be afraid of the dark with the ultra-accessible projector

Get a super-smooth experience and project pictures up to 80", enjoy a comfortable image, stereo sound and all the connectivity you need for streaming your favourite content.

Remarkable pictures

- Project images up to 80"
- Customise your projection
- Advanced LED Light Source

Play, connect, repeat

- Built-in Media Player for unlimited binge watching
- Fully Connected (HDMI, USB, VGA or MicroSD)
- Make It smart!

Sound everywhere

- Built-in stereo speakers for crystal-clear sound
- Audio jack

Highlights

Advanced LED Light Source



The powerful LED light source displays rich, vivid colours and will last up to 30,000 hours. You won't need to replace it as it lasts 20 years with an average usage of 4 hours per day! Additionally, the power consumption is far lower than a regular lamp-based projector, which means you benefit from a bigger screen and fully immersive experience, all through an eco-friendly device!

Customise your projection



Place the product wherever you want! The keystone correction combined with the focus technology allow you to fine-tune images to your needs and place your projector at any distance.

Project images up to 80"



Project images and videos up to 200 cm (80") from less than 2 metres from the wall.

Built-in Media Player



Pop your essentials in your hand with the integrated Media Player: Browse, watch all of your videos, listen to your music or share your latest holiday pictures.

Fully Connected




Connect any multimedia devices such as set top boxes, PC, MAC, gaming consoles and streaming devices like Fire Stick or Apple TV with the USB, HDMI or MicroSD ports.

Make It smart!




Access to unlimited content by connecting to any smart gaming consoles or TV boxes like Fire Stick or Apple TV.

Audio jack

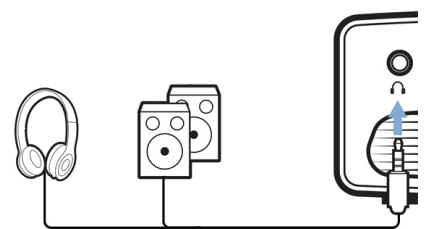

Connect any headphones or external powered speakers with the built-in 3.5 jack.

Built-in stereo speakers

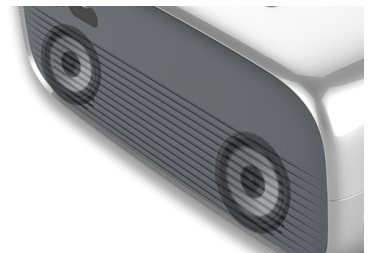

No need for extra sound systems; the built-in stereo speakers produce deep, room-filling sound perfect for films at home.

Specifications

Technology

Display technology: LCD

Light source: LED

LED lifetime: Up to 20,000h

Resolution: 800 x 480 pixel

Resolution supported: 1920 x 1080 pixels

Projection image size: up to 200 cm (80")

Projection distance: 80 cm – 200 cm/24" – 60"

Aspect ratio: 16:9

Throw ratio: 1,4:1

Contrast ratio: 3000:1

Focus adjustment: Manual

Keystone correction: Manual

Integrated media player

Sound

Stereo Speaker: 2 x 2 W

Connection

USB: x 1

HDMI: x 1

Micro SD: x 1

VGA: x 1

Audio out: 3.5 mm jack

AV in: 3.5-mm jack

DC-IN: DC jack

Power source

DC-in: 12 V, 3.5 A (AC 100–240 V)

Power consumption: Operation: 42 W, Stand by <0.5 W

Dimensions

unpacked (W x D x H): 207 x 150 x 84.5 mm/8.14 x 5.9 x 3.32 inch

Weight: 1.89 lbs/0.86 kg

