


Eaton AN19DN0A5E045

Catalog number: AN19DN0A5E045

Eaton Freedom NEMA Starter, Full voltage non-reversing, C440 electronic overload relay, NEMA Size 1 open enclosure - 27 A, Horizontal mounting, 120/60 or 110/50 coil voltage, C440 standard feature set - 9–45 A

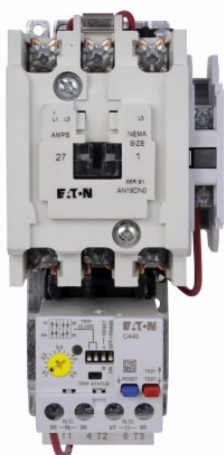

General specifications

Product Name

Eaton Freedom NEMA motor control starter

Catalog Number

AN19DN0A5E045

UPC

786685417707

Product Length/Depth

4.98 in

Product Height

7.1 in

Product Width

2.6 in

Product Weight

4 lb

Warranty

1 year

Compliances

RoHS Compliant

Certifications

UL CSA CE NEMA

[Mounting](#)

Horizontal

[Accessories](#)

Freedom NEMA

[Special features](#)

With C440 EOLR standard feature set, SEL reset, SEL class
(10a, 10, 20, 30)

[Coil voltage](#)

120/60 or 110/50

[Size](#)

1

[NEMA frame size](#)

NEMA Size 1

[Relay](#)

C440 electronic

[Type](#)

Starter

[Configuration](#)

Non-reversing

[Amperage Rating](#)

27 A

[Catalogs](#)

Eaton's Volume 5—Motor Control and Protection

[Drawings](#)

[AN19DN0_5 AutoCAD 2D Footprint \(mm\)](#)

[AN19DN0_5 2D PDF](#)

[AN19DN0_5 3D Model Xchange](#)

[AN19DN0_5 2D Drawing Xchange](#)

[AN19DN0_5 AutoCAD 2D Footprint](#)

[AN19DN0_5 3D Inventor](#)

[Specifications and datasheets](#)

[Eaton Specification Sheet - AN19DN0A5E045](#)