



TECHNICAL INFORMATION

Watts:	50
Lumens:	4300
Input Power:	AC:220-240V,50Hz
Long Life:	25,000 Hours
Unit Color:	Black
Body Type:	Die Cast Aluminium
PF:	>0.9
LED Chip Type:	SMD
CRI:	>70
Operation Temperature:	-20°C to +45°C
Beam Angle:	100°
Color Temperature:	4000K
Dimension:	198x28x167mm



FEATURES

- High quality LED SMD chip and high power driver
- Fascia glass sealed with Silicone Rubber for superior waterproof / airtight performance
- Constant current Integrated IC driver - Built in driver - no external power supply required
- Built Strong and durable with Die Cast Aluminium - Corrosion resistant design
- Suitable for building facades, sports facilities, industrial, commercial billboards, hoardings, parking lots etc.




BLACK SLIMLINE E SERIES | LED LIGHTING

V-TAC's LED Lighting range includes lighting that fulfills the needs of various end-users and industries, offering efficient and innovative products that provide modern solutions at an affordable price. We are proud to also provide an extended multi-year warranty on our products, as well as detailed support.

One brand, endless solutions..

SKU: 215959 - 50 Black

[View more details](#)

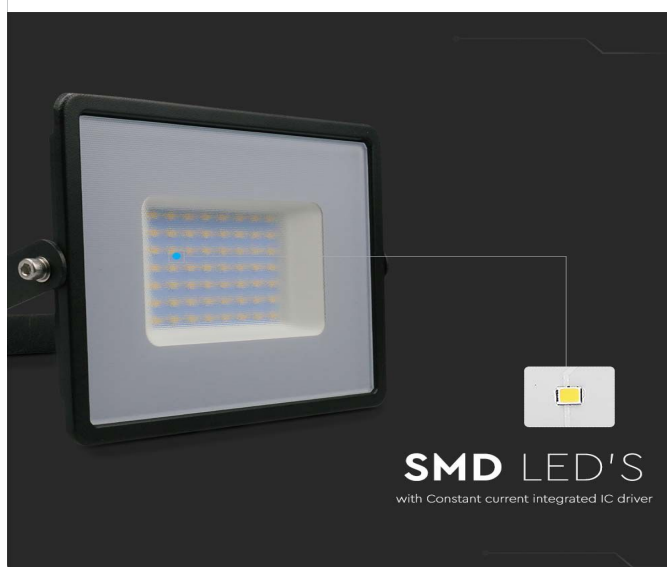

PACKAGING

Gross Weight (Kgs): 0.62
Unit CBM: 0.001562
Dimension: 198x28x167mm

MASTER BOX PACKAGING

Box Qty: 10
Length (Box) mm: 203
Width (Box) mm: 33
Height (Box) mm: 175

LISTING DETAILS

Commodity Code: 9405421000
Ean Code: 3800157681902