



## TECHNICAL INFORMATION

Watts:	6.4
Lumens:	560
Shape:	GX53
Input Power:	AC:220-240V,50Hz
Long Life:	20,000 Hours
Unit Color:	White
Body Type:	Thermoplastic
PF:	>0.5
LED Chip Type:	SMD-Samsung Chip
CRI:	>80
Operation Temperature:	-20°C to +45°C
Beam Angle:	120°
Color Temperature:	6500K
Equivalence Watts:	45
Dimension:	79x29mm


## GX53 PRO | LED LIGHTING

V-TAC's LED Lighting range includes lighting that fulfills the needs of various end-users and industries, offering efficient and innovative products that provide modern solutions at an affordable price. We are proud to also provide an extended multi-year warranty on our products, as well as detailed support.

*One brand, endless solutions..*

SKU: 21224 - 6.4 White

[View more details](#)

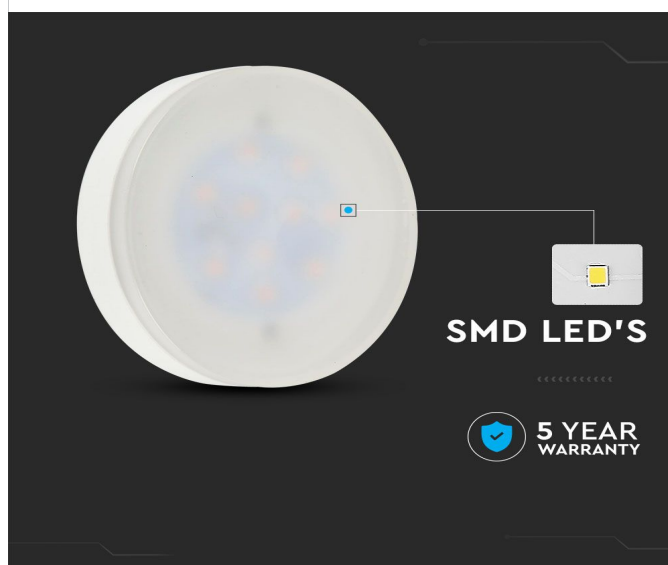

## FEATURES

- Modern LED SMD-Samsung Chip technology for better reliability and durability
- Replaces 45 watts old halogen lamp
- Lasts hours, longer life span than Standard halogen spotlights
- High luminous efficacy and low power consumption
- Designed for GX53 standard holder
- Suitable for residential lighting, commercial lighting, decorative, living rooms, lounges etc.

## PACKAGING

Gross Weight (Kgs): 0.03  
Unit CBM: 0.000204  
Dimension: 79x29mm

## MASTER BOX PACKAGING

Box Qty: 10  
Length (Box) mm: 40  
Width (Box) mm: 100  
Height (Box) mm: 80

## LISTING DETAILS

Commodity Code: 85395200  
Ean Code: 3800157677646