



[Home](#) / [Printers and Scanners](#) / [Printers by Brand](#) / [Portable Printers](#) / [M210 Label Maker](#) / [M210 Handheld Label Maker](#)


M210 Handheld Label Maker



M210 Handheld Label Maker

[Overview](#) [Specifications](#) [Support](#) [Related Items](#)



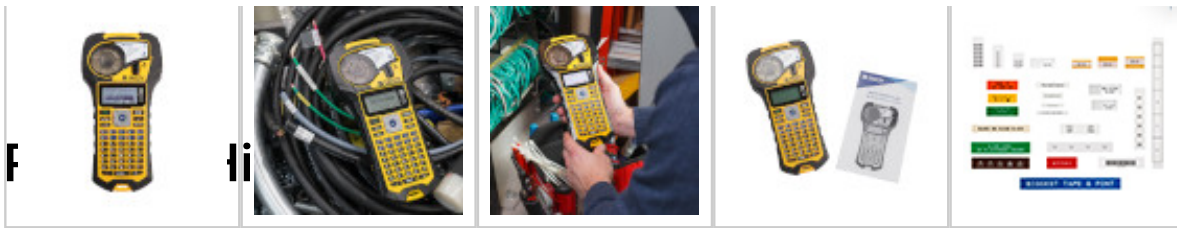

Maximum Label/Tape Width: 0.75 in
Color Printing Capability: Single Color
Maximum Labels per Day: 100
Stand Alone Printing: Stand-alone
Print Resolution: 203 dpi
Print Technology: Thermal Transfer
Part Number: M210

[CONTACT US](#)

Overview

Take on your toughest on-site labeling challenges with the M210 Label Printer. Create fast, reliable and pre-sized labels with more material. Simply drop in a cartridge, type and print.

- Create and print using a simple and intuitive keypad
- Get fast and accurate labels on-site using auto-formatting with 11 pre-loaded application design guides
- Design the custom labels you need for any application – including text and UPC, DataMatrix and QR Codes
- Take on the toughest labeling jobs – Military-grade shock and vibration resistance per MIL-STD-810G Method 5.16.6 SA4.6.5. Drop it. Kick it. Love it.
- Seamlessly transition from old to new cartridges in a snap
- Conveniently store up to 12 label files up to 2MB
- Choose from 90 compatible, easy-to-load cartridges made from 12 material types
- To receive the Li-Ion battery (M210-BATTERY) and AC Adapter/Battery Charger (M210-AC), consider the kit: M210-KIT. It includes: M210 Label Printer, AC Adapter/Battery Charger, M21 Series Nylon Cloth Patch Panel and Wire and Cable Labels, Li-Ion Rechargeable Battery, Quick Start Guide, Replacement Power Cord and Hard Case.

Specifications

Key Characteristics

Product Number	152260
UPC	888434559475
UOM	Each
Trade Name	M210



Brand Name	Brady®
Country of Origin 	Malaysia
HTS Code (Harmonized Tariff Schedule) 	8443.32.1050
ECCN (Export Commodity Control Number) 	EAR99


Dimensions

Dimensions	9.5 in H x 4.5 in W x 2.5 in D
Height	9.5 in
Width	4.5 in
Depth	2.5 in
Display Size	2 x 1 in
Weight	1.653 lb




Material Characteristics

Color	Yellow, Black
--------------	---------------

Product Features





Application 	Data and Telecommunications Labeling, Electrical Labeling, General Identification, Lean and 5S Labeling, Warehouse Marking, Wire and Cable Labeling
--	---




Shipped With Battery	No
Battery Weight (metric)	0.21 lb
Built-In Label Wizards	Flags, Patch Panel, Terminal Block, Wire Wrap
Connectivity Options 	None
Cutter Type	Single Hand Manual Actuate, Straight Cut, With label retention
Display Type	Monocolor LCD Screen
Keyboard Type	ABC
Memory	16 MB (2 MB available for storage, stores 12 labels)
Stand Alone Printing 	Stand-alone
Number of Symbols	193
Plug Type	US
Power Supply Voltage	110 - 240 V
Auto Shut-Off / Power Conserve	10 minutes
Recharge Time 	2.5 hours
User Interface Type	ABC Keypad
Battery Type	Optional AA Battery, Optional Rechargeable Lithium-Ion Battery

Printing Specifications



Barcode Symbologies - 2D	Data Matrix, QR code
Barcode Symbologies - Linear	Code 128, Code 39
Calibration Required? 	Automated through Smart Cell
Color Printing Capability	Single Color
Font Sizes	6 - 40 pt
Font Styles	Brady Standard Font
Label Retention Feature 	Yes
Maximum Labels per Day 	100
Minimum Label Length 	0.915 in
Maximum Print Speed	0.393 in/s
Minimum Liner Width	0.453 in
Print Resolution	203 dpi
Print Technology	Thermal Transfer
On Screen Indicators	Battery Life, Ribbon and label part number recognition, Ribbon Remaining, Supply Remaining
Device Drop Test & Durability	Resistant to 6-foot drops

Compatibility

Compatible Media 	M21-
Label Material Types	Heat-shrink Polyolefin, Nylon Cloth, Paper, Polyester, Polypropylene Self-





	laminating Polyester, Self-laminating Vinyl, Vinyl
Continuous & Die-Cut Materials Supported	Continuous and Die-cut
Custom Media Parts Available	No
Custom Labels Available	No
Maximum Label/Tape Width	0.75 in
Maximum Print Width	0.63 in
Maximum Printed Label Length	36 in
Maximum Liner Width	0.875 in
Languages Available	Croatian, Czech, Danish, Dutch, English (US), Estonian, Finnish, French (France), German, Hungarian, Italian, Norwegian, Polish, Portuguese (Portugal), Romanian, Slovak, Slovenian, Spanish (universal), Swedish, Turkish

What's Included

Includes	(1) M21 Series Nylon Cloth Patch Panel and Wire and Cable Labels (M21-750-499), (1) Quick Start Guide, (1)M210 Label Printer (M210)
Warranty (North America)	2 Years

Compliance

UNSPSC 	45101520	
---	----------	---

Patent Number(s)	6.604.874;6.732.619;US 8.322.936
RoHS Compliance Status	Compliant with Directive 2011/65/EU and 2015/863

Related Items



Soft Case for BMP51, M210, M211, BMP21-PLUS Printers

BMP-SC-1

Support

LITERATURE

M210 Info Sheet
M210 and M210-LAB Portable Label Printer Quick Start Guide

M210 and M210-LAB User Manual Portable Printer Product



M210 and M210-LAB User Manual | PORTABLE PRINTER BROCHURE

Portable Printer Brochure

[SHOW MORE](#)

