



[Home](#) / [Printers and Scanners](#) / [Printers by Application](#) / [DataCom Printers](#) /  
M211 Portable Bluetooth Label Printer with Accessory Kit


# M211 Portable Bluetooth Label Printer with Accessory Kit



M211 Portable Bluetooth Label Printer with Accessory Kit

[Overview](#) [Specifications](#) [Support](#)



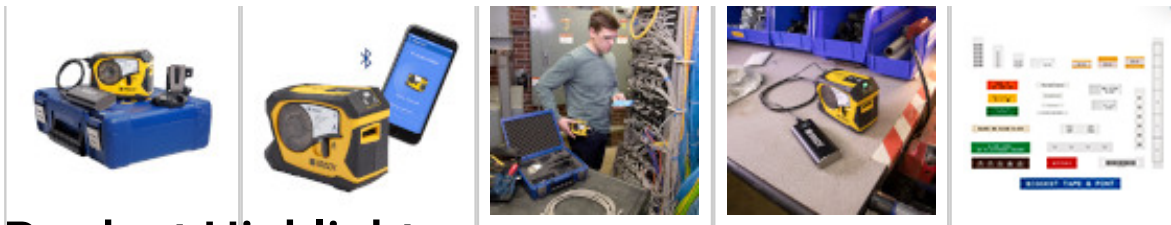

## Product Highlights

**Maximum Label/Tape Width:** 0.75 in

**Color Printing Capability:** Single Color

**Maximum Labels per Day:** 100

**Stand Alone Printing:** Mobile device connected

**Print Resolution:** 203 dpi

**Print Technology:** Thermal Transfer

**Part Number:** M211-KIT

[CONTACT US](#)

---

## Overview



Design. Preview. Print. All from your phone. This M211 Label Printer Kit includes all the accessories you need for a seamless, on-demand experience.



- Seamlessly design, preview and print labels right from our industry-leading Express Labels Mobile App
- Make any workspace easier to navigate with the attachable magnet for hands-free label creation
- Conveniently store and protect your printer, labels and accessories with a premium hard case
- Work more effectively with the hands-free portability the M211 Belt Clip provides
- Quickly charge your label printer, phone or tablet with the M211 Power Brick
- Includes: M211 Printer, M21-750-499 Label Cartridge, Quick Start Guide, AC Adapter, Belt Clip, Power Brick, Hard Case and Magnet

## Specifications

### Key Characteristics

Product Number	170383
UPC	888434587546
UOM	Kit
Trade Name	M211
Brand Name	Brady®
Country of Origin 	Malaysia



<b>HTS Code (Harmonized Tariff Schedule)</b> 	8443.32.1050
<b>ECCN (Export Commodity Control Number)</b> 	EAR99


## Dimensions

<b>Dimensions</b>	4 in H x 5.4 in W x 2.6 in D
<b>Height</b>	4 in
<b>Width</b>	5.4 in
<b>Depth</b>	2.6 in
<b>Weight</b>	1.2 lb




## Material Characteristics

<b>Color</b>	Yellow, Black
--------------	---------------

## Product Features

<b>Application</b> 	Data and Telecommunications Labeling, Electrical Labeling, General Identification, Lean and 5S Labeling, Warehouse Marking, Wire and Cable Labeling
<b>Shipped With Battery</b>	Yes
<b>How Is Battery Shipped</b>	Shipped installed in equipment
<b>Battery mAh Rating</b>	1200 mAh







<b>Built-In Label Wizards</b>	Breaker Box, Flags, General, Patch Panel, Pipe Marker, Safety, Terminal Block, Wire Wrap
<b>Connectivity Options</b> 	Bluetooth® 5 Low Energy (class II)
<b>Cutter Type</b>	Auto Cutter, With label retention
<b>Display Type</b>	None
<b>Keyboard Type</b>	None
<b>Memory</b>	Memory via connected mobile device
<b>Stand Alone Printing</b> 	Mobile device connected
<b>Number of Symbols</b>	Dependant on software
<b>Plug Type</b>	US
<b>Power Supply Voltage</b>	110 - 240 V
<b>Auto Shut-Off / Power Conserve</b>	User Configurable, Yes
<b>Recharge Time</b> 	4 hours
<b>Special Characters Quantity</b>	Determined by software
<b>User Interface Type</b>	Mobile device
<b>Battery Type</b>	Internal, not removable, Lithium-ion Battery

## Printing Specifications


<b>Barcode Symbologies - 2D</b>	Data Matrix, PDF417, QR code
<b>Barcode Symbologies - Linear</b>	Code 128, Code 128A, Code 11



	Code 128C, Code 39, Code 39 Full ASCII, Code 93, Code 93 Full ASCII, EAN-13, EAN-13 Extension 2, EAN-13 Extension 5, EAN-8, EAN-8 Extension 2, EAN-8 Extension 5, GS1-128, HIBC, Interleaved 2 of 5, JAN-13, JAN-8, UPC-A, UPC-E
<b>Calibration Required?</b> 	Automated through Smart Cell
<b>Color Printing Capability</b>	Single Color
<b>Font Sizes</b>	4 - 150 pt
<b>Font Styles</b>	Determined by software
<b>Label Retention Feature</b> 	Yes
<b>Maximum Labels per Day</b> 	100
<b>Maximum Print Speed</b>	0.6 in/s
<b>Print Resolution</b>	203 dpi
<b>Print Technology</b>	Thermal Transfer
<b>On Screen Indicators</b>	Battery Life, Bluetooth Status, Error Messaging
<b>Device Indicators</b>	Bluetooth indicating lights: pulsing blue = broadcasting signal; solid blue = device connected or paired, Error indicating lights: pulsing orange = error, Power indicating lights: solid green = 51-100% battery life; solid orange = 21-50% battery life; solid red = 11-20% battery life; flashing red = 1-10% battery life; flashing green = charging
<b>Device Drop Test &amp; Durability</b>	Resistant to 250-lb crushes, R  t

to 6-foot drops, Resistant to military-grade shocks (MIL-STD-810G)

## Compatibility


<b>Compatible Media</b> 	M21-
<b>Label Material Types</b>	Heat-shrink Polyolefin, Nylon Cloth, Paper, Polyester, Polypropylene, Self-laminating Polyester, Self-laminating Vinyl, Vinyl
<b>Continuous &amp; Die-Cut Materials Supported</b>	Continuous and Die-cut
<b>Custom Media Parts Available</b>	No
<b>Custom Labels Available</b>	No
<b>Maximum Label/Tape Width</b>	0.75 in
<b>Maximum Print Width</b>	0.62 in
<b>Maximum Printed Label Length</b>	36 in
<b>Maximum Liner Width</b>	0.875 in
<b>Phones &amp; Tablets Supported</b>	Android devices with Android OS 5+, iPhone 5S or newer with iOS 10+
<b>Software Compatibility</b>	Express Labels Mobile App
<b>Languages Available</b>	Bahasa (Indonesian), Bahasa Malay, Bulgarian, Chinese (Traditional and Simplified), Croatian, Czech, Danish, Dutch, English (US), Estonian, Finnish, French (France), German, Hungarian, Italian, Japanese, Korean, Norwegian, Polish, Portuguese (Portugal),

	Romanian, Russian, Slovak, Slovenian, Spanish (universal), Swedish, Thai, Turkish, Vietnamese
--	---

## What's Included

<b>Includes</b>	(1) AC Adapter, (1) Belt Clip, (1) Hard Case, (1) M211 Printer, (1) M21-750-499 Label Cartridge, (1) Magnet, (1) Power Brick, (1) Quick Start Guide
<b>Warranty (North America)</b>	2 Years

## Compliance

<b>UNSPSC</b> 	45101520
<b>RoHS Compliance Status</b>	Compliant with Directive 2011/65/EU and 2015/863

## Support

### — LITERATURE

[M211 Label Printer Quick Start Guide](#)

[Portable Printer Brochure](#)

[Portable Printer Brochure](#)[M211 FAQ Sheet](#)

[M211 Label Printer User Manual](#)





[SHOW MORE](#)

---

---

