

PRO-SIGNAL



Li-Polymer IR Repeater PSG3395

Please read these instructions carefully before use and retain for future reference.

IMPORTANT SAFETY INFORMATION


When using electrical appliances basic safety precautions should always be followed.

- To prevent fire or shock hazard, do not expose this product to rain or moisture.

OVERVIEW

- Simple IR repeater with long-life rechargeable battery, allows for discreet installation of AV equipment without losing remote control functionality.

OPERATION

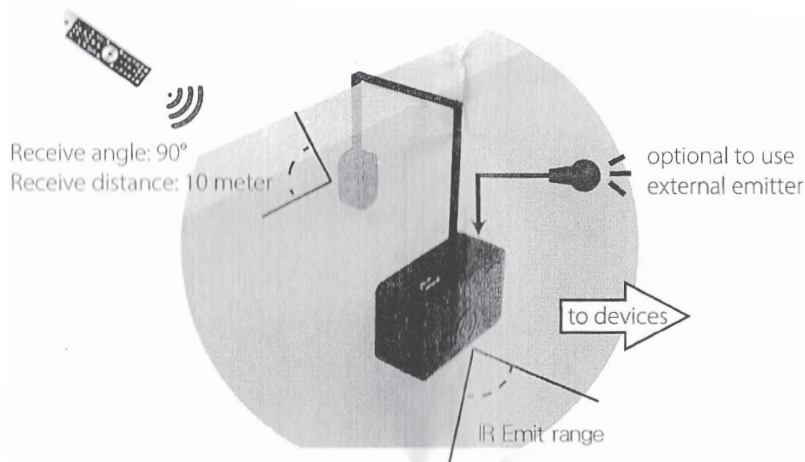

- When operation range severely reduces, the battery may require charging using any 5VDC charger with a micro USB plug.
- During charging the charging LED will illuminate and the full charge LED will illuminate when charging is complete.
- When receiving IR signal the LED on the receiver will flash.

SPECIFICATIONS

Operating range	10 meters
IR frequency	38 and 56kHz
IR emitter	Built in (optional external can be added)
Charging time	2hrs
Operating time	< 1 year (from fully charged)
Cable length	30cm
Dimensions (L x W x H)	40 x 25 x 17.5mm

- Pro-Signal declares that this radio equipment for wireless transmitter/receivers is in compliance with Radio Equipment Directive 2014/53/EU

CLEANING & MAINTENANCE

- Clean the outside casing with a soft cloth lightly moistened with a mild detergent
- Never use any abrasive or solvents.



CE
UK
UK

INFORMATION ON WASTE DISPOSAL FOR CONSUMERS OF ELECTRICAL & ELECTRONIC EQUIPMENT.

When this product has reached the end of its life it must be treated as Waste Electrical & Electronic Equipment (WEEE). Any WEEE marked products must not be mixed with general household waste, but kept separate for the treatment, recovery and recycling of the materials used. Contact your local authority for details of recycling schemes in your area.

Made in China
PO Box 13362 Dublin 2
PR2 9PP
Man Rev 1.1