

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300130060

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change A-Size Receptacle, 2 Poles, 1/2" - 14 NPT Threads, Female (Straight) to 16 AWG Leads, 0.305m (1.0') Length

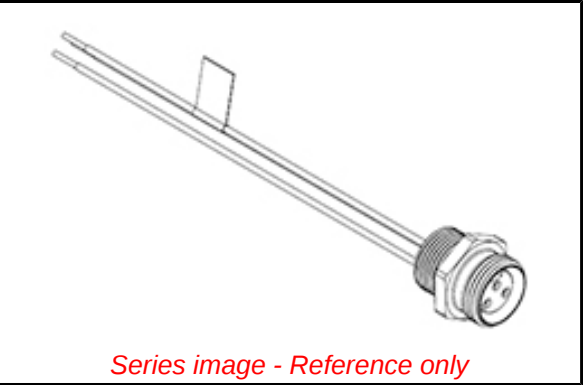

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Receptacles
Series	130013
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Taxonomy	Circular Industrial Connectors
Type	Single Ended (pigtail)
UPC	78172553087
Physical	
Coupling Type	External Thread
Gender	Female
Keyway	Single
Length	0.305m
Material - Component	Zinc Die-Cast with Black Epoxy
Mounting Thread Size	1/2" - 14 NPT
Net Weight	22.000/g
Orientation	Straight
Panel Mount	Front
Poles	2
Temperature Range - Operating	-20° to +105°C
Wire Size AWG	16
Wire/Cable Type	UL 1015
Electrical	
Current - Maximum per Contact	13.0A
Voltage - Maximum	600V AC/DC
Material Info	
Engineering Number	1R2004A20A120
Reference - Drawing Numbers	
Sales Drawing	SD-130013-060-001, SD-130013-121-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2022)4187-DC (10 June 2022)	
Lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained
ZZCERT_CE - Declaration of Conformity	CER_4000408918_00_000.pdf
ZZCERT_UKCA - Declaration of Conformity	CER_4000410285_00_000.pdf

Search Parts in this Series

130013 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION