

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300130315

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change A-Size Receptacle, 4 Poles, 1/2" NPT Threads, Female (Straight) to 16 AWG Leads, 0.3m (1.0') Length

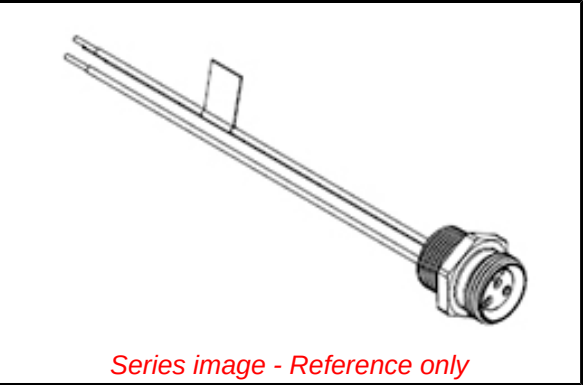

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
UL	E152210
General	
Product Family	Industrial Receptacles
Series	130013
IP Rating	IP67
NEMA Rating	NEMA 6
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Taxonomy	Circular Industrial Connectors
Type	Single Ended (pigtail)
UPC	78678805209
Physical	
Coupling Type	External Thread
Gender	Female
Keyway	Single
Length	0.305m
Material - Component	Stainless Steel
Mounting Thread Size	1/2" NPT
Net Weight	411.000/g
Orientation	Straight
Panel Mount	Front
Poles	4
Temperature Range - Operating	-20° to +105°C
Wire Size AWG	16
Wire/Cable Type	UL 1015
Electrical	
Current - Maximum per Contact	10.0A
Voltage - Maximum	600V
Material Info	
Engineering Number	1R4004A20A1201
Reference - Drawing Numbers	
Sales Drawing	SD-130013-041-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Contained Per -	
D(2022)4187-DC (10	
June 2022)	
Lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained
ZZCERT_CE -	CER_4000409978_00_000.pdf
Declaration of	
Conformity	
ZZCERT_UKCA	CER_4000410285_00_000.pdf
- Declaration of	
Conformity	

Search Parts in this Series

130013 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION