


## Datasheet

# Connector Panels – for Panel Mounting Thermocouple Sockets


Miniature Panel:

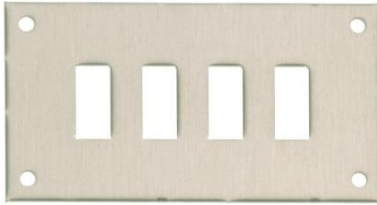

suitable with Miniature Panel Sockets (not included):



Standard Panel:

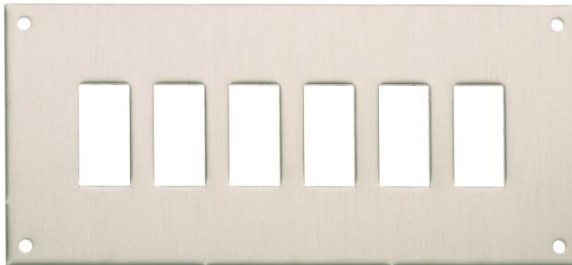

suitable with Standard Panel Sockets (not included):



- Anodised Aluminium Faceplates
- Suitable for miniature & standard fascia panel mounting thermocouple sockets
- Etch matt & satin anodised finish
- Miniature size panels available in 2, 4, 6, 12, 16, 20 & 24 way
- Standard size panels available in 1, 2, 3, 4 & 6 way
- 1 to 12 way panels in single row (as shown)
- 16, 20 & 24 way panels are in two rows i.e. 16 way = 2 rows of eight, 20 way = 2 rows of 10, 24 way = 2 rows of 12
- Both miniature & standard panels have 4 x 3.2mm fixing holes, positioned 5mm centre line from corners edges

Panel Size	No. of rows/holes	Width	Height	Thickness	order code
<b>Miniature</b>					
2 way	1 x 2	55mm	45mm	2mm	XF-1743-FAR
4 way	1 x 4	85mm	45mm	2mm	XF-1740-FAR
6 way	1 x 6	115mm	45mm	2mm	XF-118-FAR
12 way	1 x 12	205mm	45mm	2mm	XF-1745-FAR
16 way	2 x 8	145mm	75mm	2mm	XF-1741-FAR
20 way	2 x 10	175mm	75mm	2mm	XF-1742-FAR
24 way	2 x 12	205mm	75mm	2mm	XF-1744-FAR

Panel Size	No. of rows/holes	Width	Height	Thickness	order code
<b>Standard</b>					
1 way	1 x 1	50mm	66mm	2.5mm	XF-119-FAR
2 way	1 x 2	69mm	66mm	2.5mm	XF-1752-FAR
3 way	1 x 3	88mm	66mm	2.5mm	XF-1754-FAR
4 way	1 x 4	107mm	66mm	2.5mm	XF-1753-FAR
6 way	1 x 6	145mm	66mm	2.5mm	XF-120-FAR