


LTE700 IR Pass Distn Amp 8 Way

Art. Number 334094

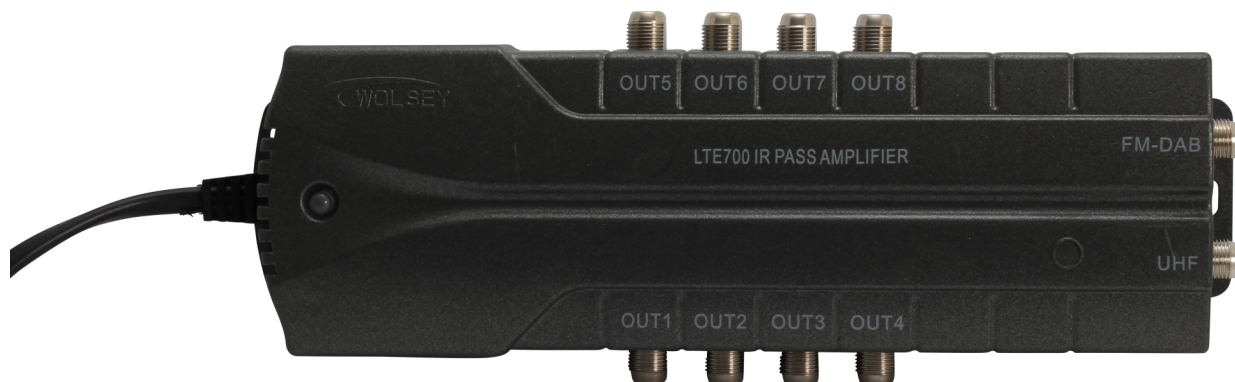

LTE 700 8 Way IR Pass Amplifier

- LTE700 protected IR Pass Distribution Amplifier
- Distributes to multiple TV's around the home
- Allows control of Sky Digital receivers when used with TRIAX Digital Links and MOD103T Modulator
- 2 Input 8 Output
- Short circuit protected in each output
- Power on LED
- Screened housing
- F-Connectors
- Easy to mount fixing

Technical Specifications

ORDER INFORMATION

EAN Number 5702663340947

CHARACTERISTICS

Max. Output level | dBμV 96.0 dBμV

FREQUENCY RANGE

Output frequency range | MHz 85...694 MHz
 Frequency range UHF | MHz 470...694 MHz
 Frequency Range FM | MHz 87.5...108 MHz
 Frequency Range DAB | MHz 217...230 MHz
 Frequency range VHF | MHz 85...230 MHz

GAIN

Gain | dB 10 +/-2 dB
 Noise figure | dB <5 dB

ELECTRICAL

Impedance | Ω 75 Ω



TRIAx

connecting the future

Technical Specifications

OPERATIONAL

AC Supply voltage | VAC 230 $\pm$ 10% / 50Hz VAC

CONNECTORS

Number of inputs 2

Number of outputs 8

MECHANICAL

Colour RAL 7016 - Anthracite grey

Packing QTY 1

Packaging Height | m 0.060 m

Packaging Width | m 0.250 m

Packaging Depth | m 0.130 m

Packaging Volume | m3 0.002 m3

Net Weight | kg 0.550 kg

Tara Weight | kg 0.110 kg

Total Weight | kg 0.660 kg

Remarks fully screened within plastic housing