

# WorkForce WF-2910DWF



Compact multifunction inkjet printer designed for homes and small offices, with Wi-Fi and mobile printing<sup>1</sup>.

This multifunction inkjet printer with Wi-Fi is stylish, compact and easy-to-use in your home office. Reduce waste and costs with A4 double-sided printing and affordable individual inks. Printing with devices on the go is easy, with Wi-Fi, Wi-Fi Direct, Epson Connect<sup>1</sup>, the Epson Smart Panel app<sup>1</sup> and Apple AirPrint<sup>2</sup>.

#### Compact and stylish

With its sleek and refined form, it's easy to integrate this space-saving, multifunction model into any home office.

#### Easy to use

The printer's functions are easy to navigate, thanks to the intuitive user interface and LCD screen. Save paper and money with A4 double-sided printing.


#### Minimise your outgoings

Epson's four-colour Pineapple 604 inks provide reliable and clear prints with minimal outlay. In addition to reducing your printing costs with affordable, individual inks in standard and XL cartridges.

#### Flexible wireless solutions


Print from anywhere in your home or office, with Wi-Fi connectivity. Or use Wi-Fi Direct to print from compatible wireless devices without a Wi-Fi network. Plus, with Epson's Smart Panel app you can control your printer from your device, printing documents, monitoring and troubleshooting<sup>1</sup>.

## DATASHEET / BROCHURE

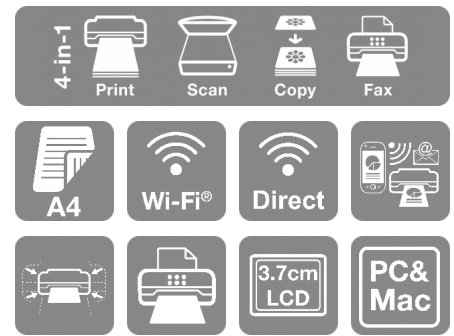

## KEY FEATURES

- **Multifunction printer with Wi-Fi**  
Print, scan, copy and fax
- **Business features**  
Business-quality documents and A4 double-sided printing
- **Easy mobile printing**  
Print easily from your smartphone or tablet<sup>1</sup>
- **Individual inks**  
Save money by only replacing the colour used
- **3.7cm LCD screen**  
Easily navigate through the printer's functions

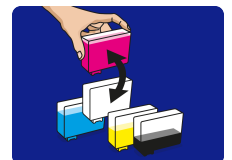

## PRODUCT SPECIFICATIONS

### TECHNOLOGY

|                      |                                   |
|----------------------|-----------------------------------|
| Printing Method      | 4-colour inkjet printer           |
| Minimum Droplet Size | 3 pl                              |
| Ink Technology       | Pigment black and Dye colour Inks |

### PRINT

|                                                                                                                                  |                                                                                                                                                                                        |
|----------------------------------------------------------------------------------------------------------------------------------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Printing Speed ISO/IEC 24734                                                                                                     | 10 pages/min Monochrome, 5 pages/min Colour                                                                                                                                            |
| Maximum Printing Speed                                                                                                           | 33 pages/min Monochrome (plain paper 75 g/m <sup>2</sup> ), 18 pages/min Colour (plain paper 75 g/m <sup>2</sup> ), 42 Seconds per 10 x 15 cm photo (Epson Premium Glossy Photo Paper) |
| Printing Resolution                                                                                                              | 5,760 x 1,440 DPI                                                                                                                                                                      |
| Printing Volume                                                                                                                  | 3,000 pages per month                                                                                                                                                                  |
|                                                                                                                                  | The maximum number of printed pages per month based on the performance capabilities of the printer, including ISO rated print speeds and paper handling capabilities.                  |
| Colours                                                                                                                          | Black, Cyan, Yellow, Magenta                                                                                                                                                           |
| For detailed information on printing speeds please visit <a href="http://www.epson.eu/testing">http://www.epson.eu/testing</a> . |                                                                                                                                                                                        |

### SCAN

|                    |                                               |
|--------------------|-----------------------------------------------|
| Optical Resolution | 1,200 DPI x 2,400 DPI (Horizontal x Vertical) |
| Scanner type       | Contact image sensor (CIS)                    |

### FAX

|                       |                                                                                                   |
|-----------------------|---------------------------------------------------------------------------------------------------|
| Fax speed dials (max) | 100 names and numbers                                                                             |
| Page memory           | Up to 100 pages (ITU-T No.1 chart)                                                                |
| Fax Functions         | PC Fax, Memory Reception, Auto Redial, Speed Dial, Address Book, Broadcast Fax, Polling Reception |

### PAPER / MEDIA HANDLING

|                       |                                                                                                                                                                      |
|-----------------------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Paper Formats         | A4 (21.0x29.7 cm), A5 (14.8x21.0 cm), A6 (10.5x14.8 cm), B5, B6, C6 (Envelope), DL (Envelope), No. 10 (Envelope), Letter, 10 x 15 cm, 13 x 18 cm, 16:9, User defined |
| Duplex                | Yes (A4, plain paper)                                                                                                                                                |
| Paper Tray Capacity   | 100 Sheets Standard, 20 Photo Sheets                                                                                                                                 |
| Number of paper trays | 1                                                                                                                                                                    |

### CONNECTIVITY

|               |                                                                                                   |
|---------------|---------------------------------------------------------------------------------------------------|
| Interfaces    | Hi-Speed USB - compatible with USB 2.0 specification, Wireless LAN IEEE 802.11b/g/n, Wi-Fi Direct |
| WLAN Security | WEP 64 Bit, WEP 128 Bit, WPA PSK (TKIP), WPA2 PSK (AES), WPA3-SAE(AES)                            |

### GENERAL

|                    |                                                                                                                                  |
|--------------------|----------------------------------------------------------------------------------------------------------------------------------|
| Energy Use         | 12 Watt (standalone copying, ISO/IEC 24712 pattern), 0.7 Watt (sleep mode), 4.6 Watt (Ready), 0.2 Watt (Power off)               |
| Product dimensions | 375 x 300 x 170 mm (Width x Depth x Height)                                                                                      |
| Product weight     | 4.4 kg                                                                                                                           |
| Noise Level        | 5.1 B (A) according to ISO 7779 pattern with Epson Premium Glossy Photo Paper / Photo RPM mode - 37 dB (A) according to ISO 9296 |

### ADDITIONAL FEATURES

|       |                               |
|-------|-------------------------------|
| Panel | Type: Color, Diagonal: 3.7 cm |
|-------|-------------------------------|

### OTHER

|          |                                                             |
|----------|-------------------------------------------------------------|
| Warranty | 12 months Carry in<br>Optional warranty extension available |
|----------|-------------------------------------------------------------|

## LOGISTICS INFORMATION

|                   |               |
|-------------------|---------------|
| SKU               | C11CK64401    |
| EAN code          | 8715946702599 |
| Country of Origin | Indonesia     |



For more information please contact:

Home users: 0343 90 37766  
Business users\*: 0871 42 37766  
Republic of Ireland: 01 436 7742  
Or visit us at <https://www.epson.co.uk/contactus>  
\* 10p per minute plus network extras.

Web: [www.epson.co.uk](http://www.epson.co.uk)  
[www.epson.ie](http://www.epson.ie)

Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners.  
Product information is subject to change without prior notice.  
Last extracted: 2022-08-11

## WorkForce WF-2910DWF

### WHAT'S IN THE BOX

- Individual Ink Cartridges
- Main unit
- Power cable
- Setup guide
- Warranty document

### INK CARTRIDGE COMPATIBILITY



### INK YIELD DATA

|       |               |                 |
|-------|---------------|-----------------|
|       | Pineapple 604 | Pineapple 604XL |
| ●     | 150 pages*    | 500 pages*      |
| ● ● ● | 130 pages*    | 350 pages*      |

\* Approx. page yield based on ISO/IEC 24711/24712 or ISO/IEC 29102/29103. Actual yield will vary depending on images printed and usage conditions. For more information visit <http://www.epson.eu/pageyield>

1. Epson Smart Panel and Epson Creative Print apps require a wireless connection. Epson Email Print, Epson Remote Print Driver require an internet connection. For more information, supported languages and devices, please visit [www.epsonconnect.eu](http://www.epsonconnect.eu)
2. AirPrint-enabled printers work with iPhone 4s and later, iPad 2 and later, all models of iPad Air and iPad mini, and iPod touch 5th generation with the latest version of iOS, and Mac with the latest version of OSX.

# EPSON®