

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1210230464](#)
Status: **Active**
Overview: mPm DIN Valve Connectors
Description: mPm DIN Valve Connector, Form C-Micro 9.4mm, PG7 Internal Threads, 3 Pole Plus Ground Terminal, 250V AC/300V DC, Black, Nitrile Gasket and Screw, Bulk Pack Mounted

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-121023-C19-001 \(PDF\)](#)

Agency Certification

UL E218123

General

Product Family Field Attachable / Accessories
Series [121023](#)
Form C - Micro 9.4mm
IP Rating IP65, IP67
Material - Contact Brass
Overview [mPm DIN Valve Connectors](#)
Product Name mPm
Taxonomy Circular Industrial Connectors
Type Field Attachable Connector
UPC 883906249076

Physical

Cable Diameter N/A
Coupling Type Internal Thread
Diagnostics / LEDs No
Diagnostics Port No
Gender N/A
Keyway None
Material - Connector Body Polypropylene
Material - Coupling Nut N/A
Material - Plating Mating Silver
Net Weight 11.553/g
Orientation 90° Angle
Pitch - Mating Interface 9.40mm
Poles 3
Temperature Range - Operating -40°C to +90°C
Wire Size AWG N/A

Electrical


Current - Maximum per Contact 16.0A
Voltage - Maximum 250V AC / 300V DC

Material Info

Engineering Number C19307N21

Reference - Drawing Numbers

Packaging Specification PK-121023-C19-001
Sales Drawing SD-121023-005-001

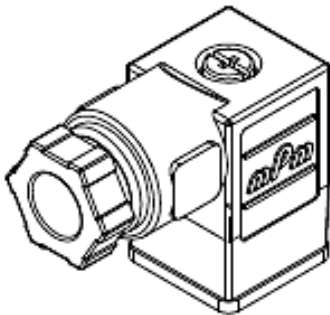

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2022)4187-DC (10 June 2022)

Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT_CE -

Declaration of

Conformity

ZZCERT_UKCA

- Declaration of

Conformity

China RoHS

50 Image

Not Relevant

Not Contained

CER_4000428677_00_000.pdf

CER_4000428678_00_000.pdf

Search Parts in this Series

[121023 Series](#)