

WorkForce WF-2960DWF



Compact multifunction printer designed for home and small offices, with double-sided printing, ADF, Wi-Fi, Ethernet and mobile printing.

You'll be surprised just how many essential business features this affordable and compact multifunction inkjet printer packs in. Connect easily via Wi-Fi and Wi-Fi Direct and print in the way that suits you with Epson Connect¹ and Apple AirPrint². Thanks to the Automatic Document Feeder (ADF) and double-sided printing, you can use your time and budget more efficiently.

Compact and stylish

There's no need to waste space; this multifunction printer features a compact design. With its sleek and refined form, it's easy to integrate into any home or small office.

Easy to use

Speed through tasks with double-sided printing, 150-sheet front-loading paper tray and 30-page ADF for multi-page scanning, copying and faxing. Navigation is easy with its large LCD touch-screen and interface.

Minimise your outgoings

Epson's four-colour 503 Chillies inks give reliable and clear prints with minimal outlay. In addition to reducing your printing costs with affordable, individual inks in standard and XL cartridges.

Flexible wireless solutions


Print from anywhere with Wi-Fi connectivity, or use Wi-Fi Direct to print from compatible wireless devices without a Wi-Fi network. Plus, with Epson's Smart Panel app you can print documents, monitor and troubleshoot¹ all from your device.

DATASHEET / BROCHURE



KEY FEATURES

- **Business features**
ADF, business-quality documents and A4 double-sided printing
- **Multifunction printer with WiFi**
Scan, copy, print and fax wirelessly
- **Easy mobile printing**
Print easily from your smartphone or tablet¹
- **Individual inks**
Save money by only replacing the colour used
- **6.1cm LCD screen**
Easily navigate through the printer's functions

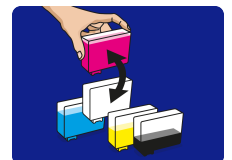

PRODUCT SPECIFICATIONS

TECHNOLOGY

Printing Method	4-colour inkjet printer
Minimum Droplet Size	3.3 pl, With Variable-Sized Droplet Technology
Ink Technology	Pigment black and Dye colour Inks

PRINT

Printing Speed ISO/IEC 24734	14 pages/min Monochrome, 7.5 pages/min Colour
Duplex Printing Speed	6.5 A4 Pages/min Monochrome, 4.5 A4 Pages/min Colour
ISO/IEC 24734	
Maximum Printing Speed	33 pages/min Monochrome (plain paper 75 g/m ²), 20 pages/min Colour (plain paper 75 g/m ²)
Printing Resolution	4,800 x 1,200 DPI
Printing Volume	3,000 pages per month
	The maximum number of printed pages per month based on the performance capabilities of the printer, including ISO rated print speeds and paper handling capabilities.
Colours	Black, Cyan, Yellow, Magenta

For detailed information on printing speeds please visit <http://www.epson.eu/testing>.

SCAN

Optical Resolution	1,200 DPI x 2,400 DPI (Horizontal x Vertical)
Scanner type	Contact image sensor (CIS)

FAX

Fax speed dials (max)	100 names and numbers
Page memory	Up to 100 pages (ITU-T No.1 chart)
Fax Functions	PC Fax, Auto Redial, Speed Dial, Address Book, Broadcast Fax, Polling Reception

PAPER / MEDIA HANDLING

Paper Formats	A4 (21.0x29.7 cm), A5 (14.8x21.0 cm), A6 (10.5x14.8 cm), B5, B6, C6 (Envelope), DL (Envelope), No. 10 (Envelope), Letter, 10 x 15 cm, 13 x 18 cm, 16:9, User defined, C4 (Envelope)
Automatic Document Feed	30 pages
Duplex	Yes (A4, plain paper)
Paper Tray Capacity	150 Sheets Standard, 20 Photo Sheets
Number of paper trays	1

CONNECTIVITY

Interfaces	Hi-Speed USB - compatible with USB 2.0 specification, Wireless LAN IEEE 802.11b/g/n, Wi-Fi Direct, Ethernet interface (100 Base-TX / 10 Base-T)
WLAN Security	WEP 64 Bit, WEP 128 Bit, WPA PSK (TKIP), WPA2 PSK (AES), WPA3-SAE(AES)

GENERAL

Energy Use	12 Watt (standalone copying, ISO/IEC 24712 pattern), 1 Watt (sleep mode), 5.4 Watt (Ready), 0.2 Watt (Power off)
Product dimensions	375 x 347 x 231 mm (Width x Depth x Height)
Product weight	6.4 kg

OTHER

Warranty	12 months Carry in Optional warranty extension available
----------	---

LOGISTICS INFORMATION

SKU	C11CK60401
EAN code	8715946702513
Country of Origin	Philippines



For more information please contact:

Home users: 0343 90 37766
Business users*: 0871 42 37766
Republic of Ireland: 01 436 7742
Or visit us at <https://www.epson.co.uk/contactus>
* 10p per minute plus network extras.

Web: www.epson.co.uk
www.epson.ie

Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners.
Product information is subject to change without prior notice.
Last extracted: 2022-11-03

WorkForce WF-2960DWF

WHAT'S IN THE BOX

- Individual Ink Cartridges
- Main unit
- Power cable
- Setup guide
- Warranty document

INK CARTRIDGE COMPATIBILITY



INK YIELD DATA

					Chillies 503	Chillies 503XL
210 pages*	165 pages*	165 pages*	165 pages*			

* Approx. page yield based on ISO/IEC 24711/24712 or ISO/IEC 29102/29103. Actual yield will vary depending on images printed and usage conditions. For more information visit <http://www.epson.eu/pageyield>

1. Epson Smart Panel and Epson Creative Print apps require a wireless connection. Epson Email Print, Epson Scan-to-Cloud and Epson Remote Print Driver require an internet connection. For more information, supported languages and devices, please visit www.epsonconnect.eu
2. AirPrint-enabled printers work with iPhone 4s and later, iPad 2 and later, all models of iPad Air and iPad mini, and iPod touch 5th generation with the latest version of iOS, and Mac with the latest version of OS X.

EPSON®