



## TECHNICAL INFORMATION

Watts:	100
Lumens:	8700
Input Power:	AC:220-240V,50Hz
Long Life:	25,000 Hours
Unit Color:	Black
Body Type:	Die Cast Aluminium
PF:	>0.9
LED Chip Type:	SMD
CRI:	>70
Operation Temperature:	-20°C to +45°C
Beam Angle:	100°
Color Temperature:	4000K
Dimension:	261x32x217mm



## FEATURES

- High quality LED SMD chip and high power driver
- Fascia glass sealed with Silicone Rubber for superior waterproof / airtight performance
- Constant current Integrated IC driver - Built in driver - no external power supply required
- Built Strong and durable with Die Cast Aluminium - Corrosion resistant design
- Suitable for building facades, sports facilities, industrial, commercial billboards, hoardings, parking lots etc.




## BLACK SLIMLINE E SERIES | LED LIGHTING

V-TAC's LED Lighting range includes lighting that fulfills the needs of various end-users and industries, offering efficient and innovative products that provide modern solutions at an affordable price. We are proud to also provide an extended multi-year warranty on our products, as well as detailed support.

*One brand, endless solutions..*

SKU: 215965 - 100 Black

[View more details](#)

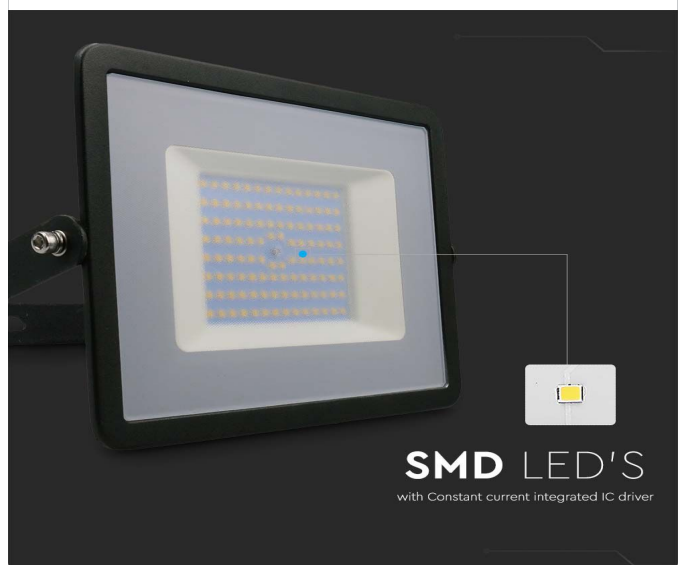

## PACKAGING

Gross Weight (Kgs): 1.13  
Unit CBM: 0.002885  
Dimension: 261x32x217mm

## MASTER BOX PACKAGING

Box Qty: 10  
Length (Box) mm: 266  
Width (Box) mm: 38  
Height (Box) mm: 227

## LISTING DETAILS

Commodity Code: 94054210  
Ean Code: 3800157681964