



TECHNICAL INFORMATION

| | |
|------------------------|---------------------|
| Watts: | 7 |
| Lumens: | 560 |
| Input Power: | AC:100-240V,50/60Hz |
| Long Life: | 20,000 Hours |
| Unit Color: | Black |
| Body Type: | ABS+Aluminium |
| LED Chip Type: | SMD |
| Operation Temperature: | -20°C to +45°C |
| Dimmable: | Yes |
| Color Temperature: | 3IN1 |
| Dimension: | 445x121x45mm |
| Input Current: | 5V, 3A |

WIRELESS CHARGING LAMPS | LED LIGHTING


V-TAC's LED Lighting range includes lighting that fulfills the needs of various end-users and industries, offering efficient and innovative products that provide modern solutions at an affordable price. We are proud to also provide an extended multi-year warranty on our products, as well as detailed support.

One brand, endless solutions..

SKU: 218602 - 7 Black

[View more details](#)

SLEEK & ELEGANT DESIGN WITH
ABS &
ALUMINUM DESIGN

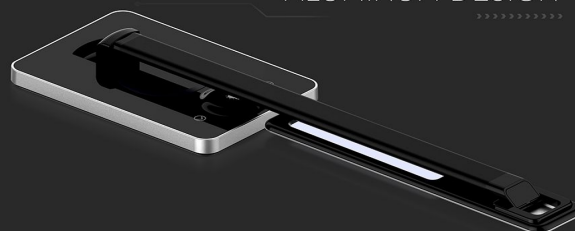

FEATURES

- Sleek and elegantly designed table lamp with wireless charging built-in
- Adjustable brightness with 3 levels of dimming
- LUX output - 800LUX
- Wireless Charging Output: 5W (5V, 1A)
- USB Output 5V, 0.5A(2.5W)
- Time to reach the brightest 2s
- Built-in Eye protection feature
- Included: 18W fast charging adapter (3A)
- Suitable for bedrooms, living rooms, offices etc.

PACKAGING

Gross Weight (Kgs): 0.7
Unit CBM: 0.004
Dimension: 445x121x45mm

MASTER BOX PACKAGING

Box Qty: 10
Length (Box) mm: 460
Width (Box) mm: 125
Height (Box) mm: 45

LISTING DETAILS

Commodity Code: 9405214000
Ean Code: 3800157686426