



TECHNICAL INFORMATION

Watts:	4
Lumens:	476
Input Power:	AC:220-240V,50Hz
Long Life:	20,000 Hours
Unit Color:	Black
Body Type:	Aluminium
LED Chip Type:	SMD
CRI:	>80
Dimmable:	No
Beam Angle:	120°
Color Temperature:	4000K
Dimension:	90x90x200mm



FEATURES

- Modern range of Up-Down lights with sleek and stylish designs
- Elegant replacement for traditional up-down lighting
- Fitted with high quality SMD chips for better reliability and longer lifespan
- Robust Aluminium build for efficient heat dissipation
- Suitable for living rooms, pathways, balconies, facades etc.


TRIANGLE LIGHT | LED LIGHTING

V-TAC's LED Lighting range includes lighting that fulfills the needs of various end-users and industries, offering efficient and innovative products that provide modern solutions at an affordable price. We are proud to also provide an extended multi-year warranty on our products, as well as detailed support.

One brand, endless solutions..

SKU: 218298 - 4 Black

[View more details](#)

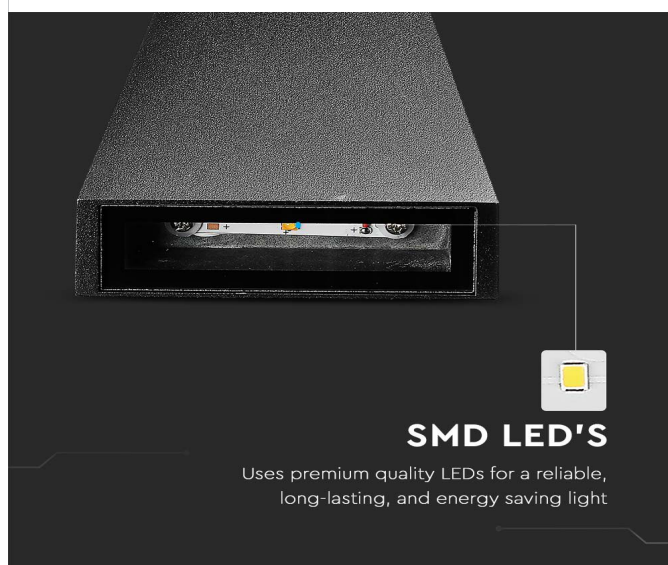

PACKAGING

Gross Weight (Kgs):	0.97
Unit CBM:	0.00358
Dimension:	90x90x200mm

MASTER BOX PACKAGING

Box Qty:	20
Length (Box) mm:	115
Width (Box) mm:	115
Height (Box) mm:	230

LISTING DETAILS

Commodity Code:	9405423990
Ean Code:	3800157681391