



TECHNICAL INFORMATION

Watts:	18
Lumens:	1800
Input Power:	AC:220-240V,50/60Hz
Long Life:	20,000 Hours
Unit Color:	White
Body Type:	Aluminium
LED Chip Type:	SMD
CRI:	>80
Dimmable:	No
Beam Angle:	90°
Color Temperature:	4000K
Dimension:	600x100x42mm



FEATURES

- Perfect choice of Interior lighting for fabulous aesthetics and appeal
- Efficient LED driver and intruded heat sink for longer lifespan
- Robust Aluminium build for efficient heat dissipation
- Suitable for decor, restaurants, residential, facades etc.


MODERN WALL LIGHTS | LED LIGHTING

V-TAC's LED Lighting range includes lighting that fulfills the needs of various end-users and industries, offering efficient and innovative products that provide modern solutions at an affordable price. We are proud to also provide an extended multi-year warranty on our products, as well as detailed support.

One brand, endless solutions..

SKU: 218534 - 18 White

[View more details](#)

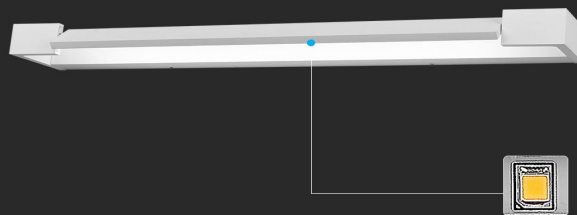

SMD LED'S

Uses premium quality LEDs for a reliable, long-lasting, and energy saving light

PACKAGING

Gross Weight (Kgs): 1.7
Unit CBM: 0.00848
Dimension: 600x100x42mm

MASTER BOX PACKAGING

Box Qty: 10

LISTING DETAILS

Commodity Code: 9405423990
Ean Code: 3800157678421