



TECHNICAL INFORMATION

Watts:	4.5
Lumens:	470
Shape:	Candle
Input Power:	AC:220-240V, 50Hz
Long Life:	20,000 Hours
Unit Color:	White
Body Type:	Thermoplastic
LED Chip Type:	SMD-Samsung Chip
CRI:	>80
Operation Temperature:	-20°C to +45°C
Beam Angle:	180°
Color Temperature:	3000K
Equivalence Watts:	40
Dimension:	36.5x100mm


CANDLE B15 PRO | LED LIGHTING

V-TAC's LED Lighting range includes lighting that fulfills the needs of various end-users and industries, offering efficient and innovative products that provide modern solutions at an affordable price. We are proud to also provide an extended multi-year warranty on our products, as well as detailed support.

One brand, endless solutions..

SKU: 21860 - 4.5 White

[View more details](#)

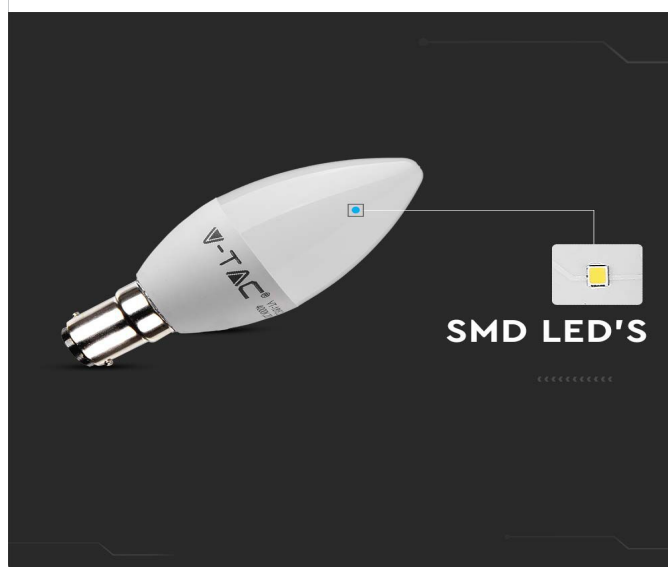

FEATURES

- Modern LED SMD-Samsung Chip technology for better reliability and durability
- Replaces 40 watts old halogen lamp
- Lasts hours, longer life span than Standard halogen lamps
- Designed for B15 standard holder
- Suitable for residential lighting, commercial lighting, decorative, living rooms, lounges etc.

PACKAGING

Gross Weight (Kgs):	0.04
Unit CBM:	0.000302
Dimension:	36.5x100mm

MASTER BOX PACKAGING

Box Qty:	192
Length (Box) mm:	39
Width (Box) mm:	39
Height (Box) mm:	102

LISTING DETAILS

Commodity Code:	8539520000
Ean Code:	3800157683357