



Color: gray Similar to illustration

Electrical data

Ratings per IEC/EN	
Ratings per	IEC/EN 60664-1
Rated voltage (III/2)	320 V
Rated impulse voltage (III/2)	4 kV
Rated current	16 A
Legend (ratings)	(III / 2) Δ Overvoltage category III / Pollution degree 2

Connection data

Connection 1	
Pole number	3

Physical data

Pin spacing	5/5.08 mm / 0.197/0.2 inches
Width	15.3 mm / 0.602 inches
Depth	6.15 mm / 0.242 inches
Jumper assignment	1-2-3

Mechanical Data

Suitable	for male and female connectors with CAGE CLAMP® connection
----------	--



Material Data	
Note (material data)	Information on material specifications can be found here
Color	gray
Material group	I
Insulation material	Polyamide (PA66)
Flammability class per UL94	V0
Fire load	0.008 MJ
Weight	0.7 g

Commercial data	
PU (SPU)	100 (25) pcs
Packaging type	Box
Country of origin	DE
GTIN	4045454565848
Customs tariff number	85366990990

Approvals / Certificates

General approvals



Approval	Standard	Certificate Name
CSA DEKRA Certification B.V.	C22.2	1466354

Downloads

Environmental Product Compliance

Compliance Search

Environmental Product Compliance 231-903

Download icon

Documentation

Additional Information


Technical Section03.04.2019pdf1949.09 KB

Download icon




Installation Notes


Installation

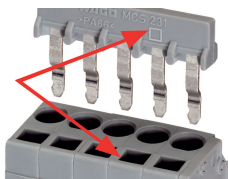


Installation

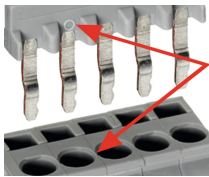


Coding

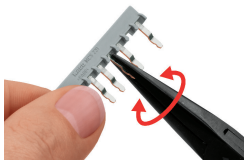

Installation

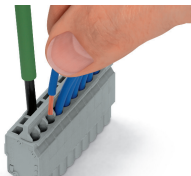

Installation

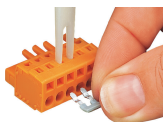

Application

