




# LEANSAFE X3

PROFESSIONAL 3 IN 1 MULTI-PURPOSE LADDER

## ALUMINIUM

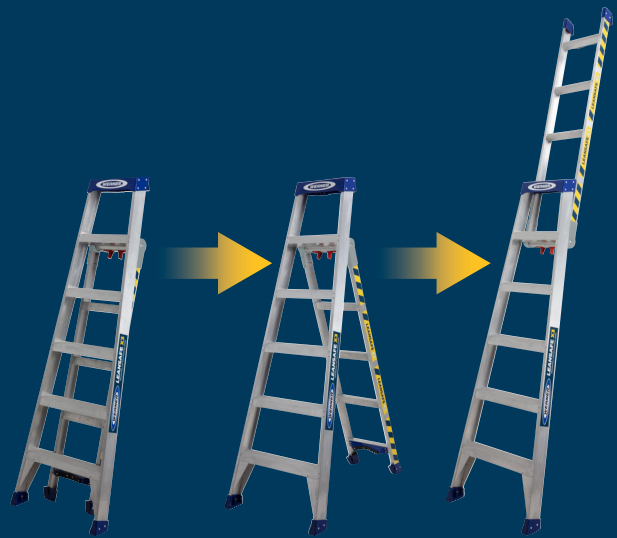

LEAN

STEP

EXTEND


One-handed  
adjustment system  
for quick and  
easy change to all  
three modes



## LIGHTWEIGHT FOR MAXIMUM FLEXIBILITY



Unique top for corner, stud  
or pole leaning

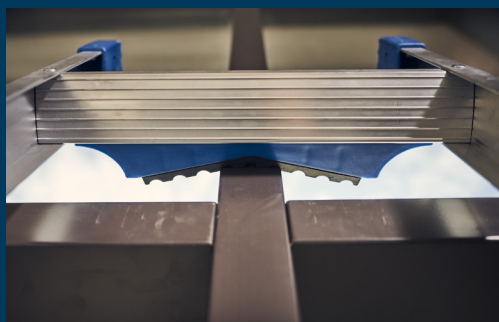

Safety grip wall bumper for pole  
or corner leaning



Compact rear section fits  
between framing studs





# LEANSAFE X3

## PROFESSIONAL 3 IN 1 MULTI-PURPOSE LADDER

# 150kg

MAX. LOAD  
(Load includes user, tools, materials, etc.)



- Made from high grade aluminium to ensure the ladder is lightweight but strong. Ideal for any job around the work site
- Combines a leaning ladder, stepladder and extension ladder all in one product

### SPECIFICATIONS

Product Code	Closed Length	Mode	Open Length	Safe Working Height*	Weight
75070	1.80m (5'11")	Leaning Ladder	1.80m (5'11")	2.85m (9'4")	9.5kg
		Stepladder	1.80m (5'11")	3.13m (10'3")	
		Extension Ladder	2.90m (9'6")	3.70m (12'1")	

\*Based on 2m as the average reach height of a person.



Safety grip wall bumper provides firm grip for pole or corner leaning



Integral tool tray with magnetic tray securely holds tool and equipment



One-handed adjustment system

Slip-resistant, reinforced rubber feet for added safety

Wide, heavy-duty slip-resistant rungs for comfort and security



Unique top designed for any leaning mode

Non-marring wall bumpers protect work surfaces from damage

Locking latch to prevent the section separating when being stored

Compact rear section fits between framing studs to get closer to the work

Foot brace provides maximum strength to protect against damage



SEE THE VIDEO



EN131

Suitable for Professional & Non-professional use

